



Type label identification, laser


Helatag 1101 (White)

A range of high quality materials and label sizes printable on standard office laser printers are available. These labels are ideal for printing high definition text, barcodes and logos in low to medium volume applications.

TagPrint Pro labelling program comes pre-loaded with all our labels. Designing labels is simply done; just choose inbuilt graphics or download your own and add data from ERP system or standard office programs such as Excel. Barcodes are created in a couple of clicks.

Features and Benefits

- White rating labels for component marking
- Crisp and clear text, barcodes and graphics
- Rounded edge design gives additional bonding strength
- Simple and efficient label design and printing with TagPrint Pro labelling software
- PDF templates available from www.HellermannTyton.co.uk for those wishing to use MS Word
- Clear protective box to ensures labels stay as good as new

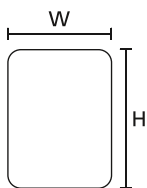

Helatag label for a permanent asset identification.

MATERIAL	Type 1101, Polyester (PET), white (WH)
Operating Temperature	-40 °C to +150 °C
Curing Temperature	from 0 °C
Adhesive	Acrylic
Thickness of Foil (µm)	60 µm
Chem. Material Properties	Excellent resistance against water, alcohol, most oils, lubricants, fuels, aliphatic solvents, weak acid, salts, alkalis and UV light.
Specifications	UL-Recognised



TYPE	Width (W)	Height (H)	Labels per Sheet	Sheets per Pack	Pack Cont.	Colour	Article-No.
TAG156LA4-1101-WH	10.2	10.2	532	19	10,000 pcs.	White (WH)	594-81101
TAG122LA4-1101-WH	15.0	9.0	372	27	10,000 pcs.	White (WH)	594-31101
TAG120LA4-1101-WH	15.2	6.4	528	19	10,000 pcs.	White (WH)	594-11101
TAG11LA4-1101-WH	16.5	5.1	605	17	10,000 pcs.	White (WH)	594-01101
TAG154LA4-1101-WH	17.0	9.0	341	30	10,000 pcs.	White (WH)	594-61101
TAG124LA4-1101-WH	19.0	11.0	260	20	5,000 pcs.	White (WH)	594-11017
TAG13LA4-1101-WH	19.1	6.4	440	23	10,000 pcs.	White (WH)	594-41101
TAG121LA4-1101-WH	20.0	8.0	315	32	10,000 pcs.	White (WH)	594-21101
TAG155LA4-1101-WH	25.4	8.5	231	22	5,000 pcs.	White (WH)	594-71101
TAG15LA4-1101-WH	25.4	12.7	154	33	5,000 pcs.	White (WH)	594-91101
TAG62LA4-1101-WH	31.8	9.5	180	28	5,000 pcs.	White (WH)	594-11016
TAG162LA4-1101-WH	38.1	12.7	110	23	2,500 pcs.	White (WH)	594-11010
TAG150LA4-1101-WH	48.3	8.5	132	19	2,500 pcs.	White (WH)	594-51101
TAG163LA4-1101-WH	48.3	12.7	88	29	2,500 pcs.	White (WH)	594-11011
TAG165LA4-1101-WH	48.3	21.2	52	20	1,000 pcs.	White (WH)	594-11012
TAG169LA4-1101-WH	48.3	33.9	32	32	1,000 pcs.	White (WH)	594-11013
TAG170LA4-1101-WH	63.5	33.9	24	21	500 pcs.	White (WH)	594-11014
TAG171LA4-1101-WH	210.0	297.0	1	25	25 pcs.	White (WH)	594-11015

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



For product specific approvals and specifications please refer to the Appendix.