



Self-laminating labels, manual marking

HELASIGN, Material 1402, Booklet

A quick and simple on-site solution for either permanent or temporary marking of wires, cables and pipes.


Features and Benefits

- Self-laminating labels supplied in handy pocket-sized booklets
- Booklet cover protects labels when stored
- Ideal for low volume maintenance and repair work
- Easy to write on and dispense labels
- Laminating function gives excellent protection against humidity and mechanical abrasion
- Applicator tool for clean application enclosed
- Write text with specially formulated fast-drying ink T82 pens



Always on hand: Labels in a convenient, pocket sized and lightweight booklet.

MATERIAL	Type 1402, Vinyl (PVC)
Operating Temperature	-40 °C to +80 °C
Curing Temperature	from +8 °C
Adhesive	Acrylic
Thickness of Foil (µm)	80 µm
Chem. Material Properties	Resistant to water, oil and many solvents.

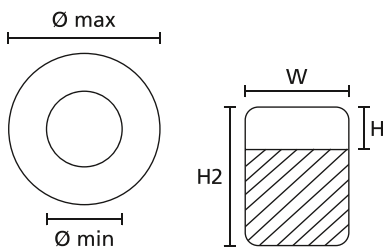

TYPE	Bundle Ø min.	Bundle Ø max.	Width (W)	Height (H)	Height (H2)	Pack Cont.	Colour	Article-No.
HSMB-C1-1402-WH	4.0	8.1	12.7	12.7	38.1	240 pcs.	White (WH), Transparent (CL)	598-14020
HSMB-C2-1402-WH	6.1	12.1	19.1	12.7	50.8	120 pcs.	White (WH), Transparent (CL)	598-14026
HSMB-C3-1402-WH	9.1	18.2	25.4	19.1	76.2	60 pcs.	White (WH), Transparent (CL)	598-21402
HSMB-C4-1402-WH	16.2	32.3	25.4	25.4	127.0	30 pcs.	White (WH), Transparent (CL)	598-40402
HSMB-C5-1402-WH	20.2	40.3	25.4	25.4	152.4	30 pcs.	White (WH), Transparent (CL)	598-50402

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

TYPE	Description	Colour	Pack Cont.	Article-No.
T82S-BK	Indelible Marker Pen	Black (BK)	2 pcs.	500-50820
T82R-RD	Indelible Marker Pen	Red (RD)	2 pcs.	500-50822

Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.