




Tamper evident security labelling, thermal transfer

Helatag 951 (Silver, Transparent), 2 parts


For automotive and electric industries for tamper-proof applications. Particularly suitable as a type label according to norms of German Kraftfahrtbundesamt (KBA).

Features and Benefits

- 2-part label, delivered on reel together with the protective label
- Designed for highly visible and rugged identification on trucks and trailers
- Tamper evident, when pulled off a checkered pattern will be visible as evident
- High durability in outside use
- Meets requirements of the KBA (Kraftfahrtbundesamt [German Federal Motor Transport Authority])
- Thickness of 951A label 36 µm, and 951B laminate 25 µm
- Particularly suitable as type label for vehicles
- Excellent print performance using TT822OUT ribbon
- Print with TT4000+, TT430 for best results
- Easy label design with TagPrint Pro

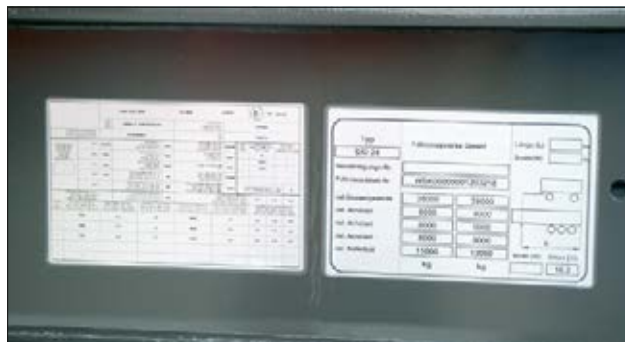


Type plate of an HGV trailer with protective laminate.

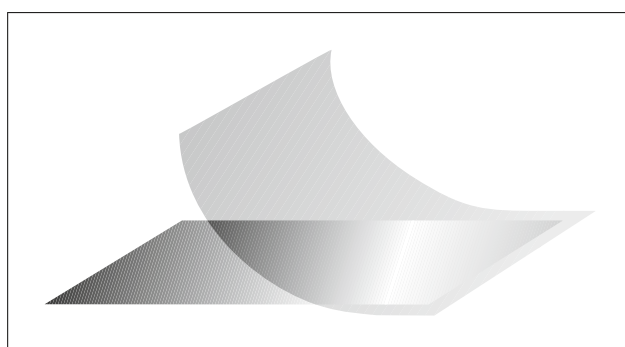

The printed silver type plate (Mat. 951A) is protected by the transparent laminate (Mat. 951B).

MATERIAL	Type 951, Polyester, silver (SR) and Polyester, transparent (CL)
Operating Temperature	-40 °C to +150 °C
Curing Temperature	from 0 °C (label), from +4 °C (laminate)
Adhesive	Acrylic
Thickness of Foil (µm)	36 µm, 25 µm
Chem. Material Properties	Excellent resistance to water, alcohol, most oils, greases, fuel, aliphatic solvents, weak acids, salts and alkalis.
Recommended Ribbon Type	TT822OUT
Specifications	KBA (Kraftfahrzeugbundesamt) Germany, UL-Recognised

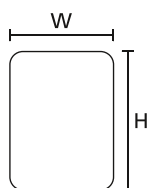

TYPE	Width (W)	Height (H)	Width of Liner (WL)	Labels per Row	Pack Cont.	Colour	Article-No.
TAG25.4-12.7TD1-951 SET	25.4	12.7	31.5	1	1,000 pcs.	Silver (SR)	596-44951
TAG50.8-25.4TD1-951 SET	50.8	25.4	56.8	1	1,000 pcs.	Silver (SR)	596-43951
TAG63.5-50.8TD1-951 SET	63.5	50.8	69.5	1	500 pcs.	Silver (SR)	596-42951
TAG101-74TD1-951 SET	101.6	74.0	107.0	1	250 pcs.	Silver (SR)	596-41951
TAG101-160TD1-951 SET	101.6	160.0	105.8	1	250 pcs.	Silver (SR)	596-40951

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



For product specific approvals and specifications please refer to the Appendix.