


Data Sheet

300pcs Non-Insulated Cable Ferrules assortment-mini kit set, 0.75mm² / 1.0mm² / 1.5mm² / 2.5mm²



Material: Copper
 Operating Temperature: 105°C (max.)

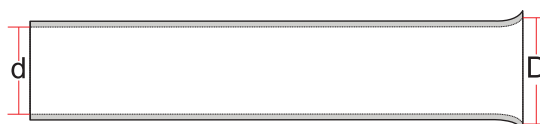

Wire range	Diameter D \emptyset	Diameter d \emptyset	Length	contents
0.75 mm ²	2.3 mm	1.2 mm	8 mm	100pcs
1.0 mm ²	2.5 mm	1.4 mm	8 mm	100pcs
1.5 mm ²	2.8 mm	1.7 mm	8 mm	50pcs
2.5 mm ²	3.4 mm	2.2 mm	8 mm	50pcs