


Data Sheet

135pcs Non-Insulated Cable Ferrules assortment-mini kit set, 4.0mm² / 6.0mm² / 10mm² / 16mm²



Material: Copper
 Operating Temperature: 105°C (max.)

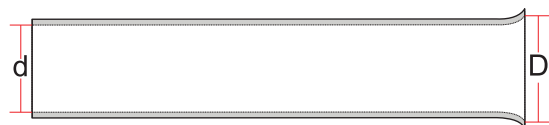

Wire range	Diameter D \emptyset	Diameter d \emptyset	Length	contents
4.0 mm ²	4.0 mm	2.8 mm	10 mm	50pcs
6.0 mm ²	4.7 mm	3.5 mm	12 mm	50pcs
10 mm ²	5.8 mm	4.5 mm	12 mm	25pcs
16 mm ²	7.5 mm	5.8 mm	12 mm	10pcs