



► (RT) Standard Bayonet Type
RT-M05-L030-K02.R

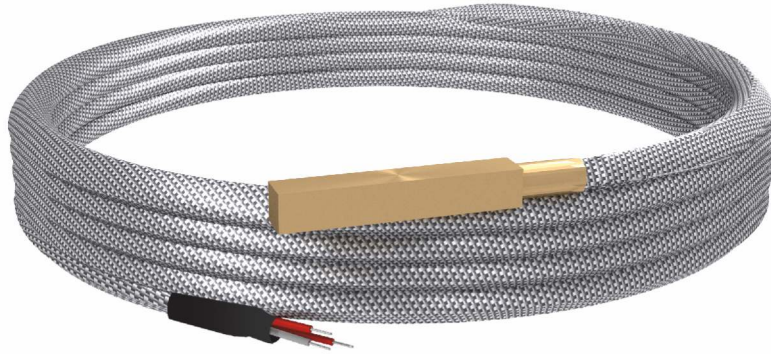


Max. operating temperature : -50 C / +400 C
Standard cable types : Fiber glass + fiber glass + braided wire
Sensor type : DIN/EN60751 Class "B" 1 x PT-100
Protection tube material : Messing

► Technical drawing

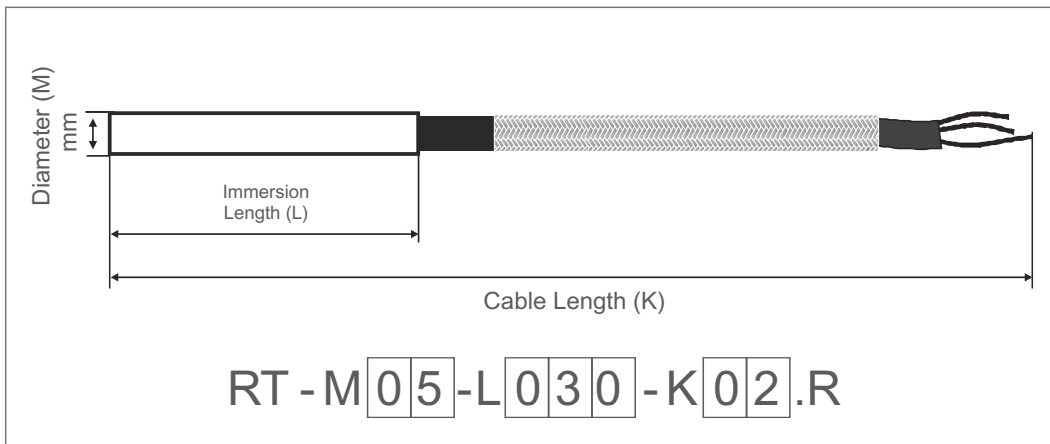

PT-100 Connections

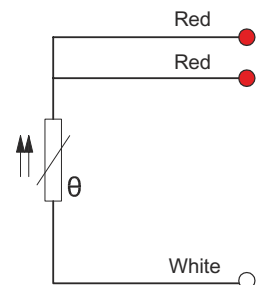

Diameter (M) : 5 mm
Immersion Length (L) : 30 mm
Cable Length (K) : 2 meter