


Data Sheet

1020pcs Non-Insulated Cable Ferrules - assortment Set



Non-Insulated cable ferrules

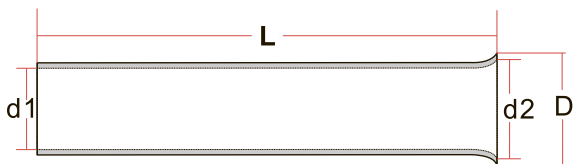

Material: Tinned Copper (EN13600)
 Operating Voltage: 600V max.
 Operating Temperature: 120°C max.

Wire range	L	D	d1	d2	Contents
0,75 mm ²	8 mm	ø 2,3 mm	ø 1,2 mm	ø 1,5 mm	250 pcs
1,0 mm ²	8 mm	ø 2,5 mm	ø 1,4 mm	ø 1,7 mm	250 pcs
1,5 mm ²	8 mm	ø 2,8 mm	ø 1,7 mm	ø 2,0 mm	200 pcs
2,5 mm ²	8 mm	ø 3,4 mm	ø 2,2 mm	ø 2,5 mm	200 pcs
4,0 mm ²	10 mm	ø 4,0 mm	ø 2,8 mm	ø 3,2 mm	50 pcs
6,0 mm ²	12 mm	ø 4,7 mm	ø 3,5 mm	ø 3,9 mm	40 pcs
10 mm ²	12 mm	ø 5,8 mm	ø 4,5 mm	ø 4,9 mm	20 pcs
16 mm ²	12 mm	ø 7,5 mm	ø 5,8 mm	ø 6,2 mm	10 pcs