


## Data Sheet

# 300pcs Twin cable Ferrules - assortment Set

Item no.: T1903C035



### Twin Cable ferrules

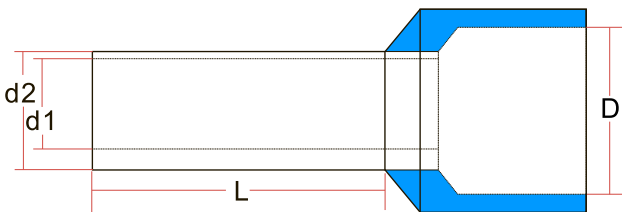

Insulation material: PVC  
 Terminal material: Tinned Copper  
 Operating Voltage: 300V max.  
 Operating Temperature: 105°C max.

Wire range	L	D	d1	d2	Contents
2 x 0,75 mm <sup>2</sup>	8 mm	ø 5,5 mm	ø 1,8 mm	ø 2,1 mm	70 pcs
2 x 1,0 mm <sup>2</sup>	8 mm	ø 5,5 mm	ø 2,0 mm	ø 2,3 mm	70 pcs
2 x 1,5 mm <sup>2</sup>	8 mm	ø 6,4 mm	ø 2,3 mm	ø 2,6 mm	50 pcs
2 x 2,5 mm <sup>2</sup>	10 mm	ø 8,0 mm	ø 2,9 mm	ø 3,3 mm	50 pcs
2 x 4,0 mm <sup>2</sup>	12 mm	ø 8,8 mm	ø 3,8 mm	ø 4,2 mm	20 pcs
2 x 6,0 mm <sup>2</sup>	14 mm	ø 9,5 mm	ø 4,9 mm	ø 5,3 mm	20 pcs
2 x 10 mm <sup>2</sup>	14 mm	ø 12,6 mm	ø 6,5 mm	ø 6,9 mm	10 pcs
2 x 16 mm <sup>2</sup>	14 mm	ø 19,0 mm	ø 8,3 mm	ø 8,7 mm	10 pcs