


Data Sheet

Insulated Crimp Ring Terminal Connector Set



Insulator material: Vinyl
Terminal material: Copper
Working Temperature: 75°C max.
Rating voltage: 600 V/AC max.
Rating current:
Red - 9 Amp. max.
Blue - 15 Amp. max.
Yellow - 20 Amp. max.

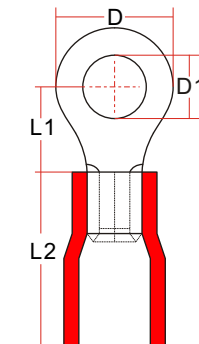

Type	Dimension(mm)				Wire range		Color	Contents
	øD1	øD2	L1	L2				
T1904C059	4.3	6.6	6.3	10	0.5-1.5 mm ²	22-16 AWG	Red	25pcs
T1904C060	4.3	6.6	6.3	11	1.5-2.5 mm ²	16-14 AWG	Blue	25pcs
T1904C061	5.3	8.0	7.0	10	0.5-1.5 mm ²	22-16 AWG	Red	25pcs
T1904C062	5.3	8.0	7.0	11	1.5-2.5 mm ²	16-14 AWG	Blue	25pcs
T1904C063	8.4	15.0	13.5	13	4.0-6.0 mm ²	12-10 AWG	Yellow	10pcs