


Data Sheet

Insulated Crimp Bullet Disconnecter Set



Insulator material: Vinyl
 Terminal material: Copper
 Working Temperature: 75°C max.
 Rating voltage: 600 V/AC max.
 Rating current:
 Red - 9 Amp. max.
 Blue - 15 Amp. max.
 Yellow - 20 Amp. max.

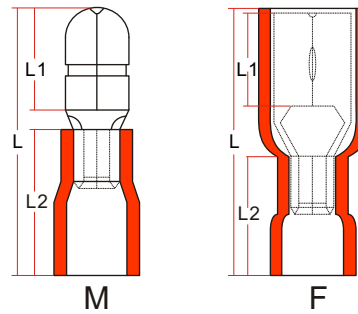

Type	Dimension(mm)	Dimension(mm)			Wire range	Color	Contents
		L	L1	L2			
T1904C048	M	20.5	8.5	10	0.5-1.5 mm ² 22-16 AWG	Red	25pcs
T1904C049	M	21.5	8.5	11	1.5-2.5 mm ² 16-14 AWG	Blue	25pcs
T1904C120	M	26.0	9.0	13	4.0-6.0 mm ² 12-10 AWG	Yellow	15pcs
T1904C050	F	22.0	7.0	10	0.5-1.5 mm ² 22-16 AWG	Red	25pcs
T1904C051	F	23.0	7.0	11	1.5-2.5 mm ² 16-14 AWG	Blue	25pcs
T1904C121	F	24.0	7.3	13	4.0-6.0 mm ² 12-10 AWG	Yellow	15pcs