
 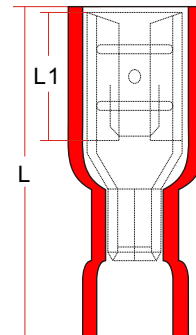


Data Sheet

Fully Insulated Crimp Female Disconnecter Set



Insulator material: Vinyl
 Terminal material: Copper
 Working Temperature: 75°C max.
 Rating voltage: 600 V/AC max.
 Rating current:
 Red - 9 Amp. max.
 Blue - 15 Amp. max.
 Yellow - 20 Amp. max.

Type	Dimension(mm)			Wire range	Color	Contents
	TAB	L1	L			
T1904C113	0.8 x 2.8 mm	6.4	21.0	0.5-1.5 mm ² 22-16 AWG	Red	25pcs
T1904C114	0.8 x 2.8 mm	6.4	21.0	1.5-2.5 mm ² 16-14 AWG	Blue	25pcs
T1904C115	0.8 x 4.8 mm	6.4	23.0	0.5-1.5 mm ² 22-16 AWG	Red	25pcs
T1904C116	0.8 x 4.8 mm	6.4	20.0	1.5-2.5 mm ² 16-14 AWG	Blue	25pcs
T1904C117	0.8 x 6.3 mm	8.0	25.0	0.5-1.5 mm ² 22-16 AWG	Red	25pcs
T1904C118	0.8 x 6.3 mm	6.4	22.0	1.5-2.5 mm ² 16-14 AWG	Blue	25pcs
T1904C119	0.8 x 6.3 mm	8.0	24.0	4.0-6.0 mm ² 12-10 AWG	Yellow	15pcs