
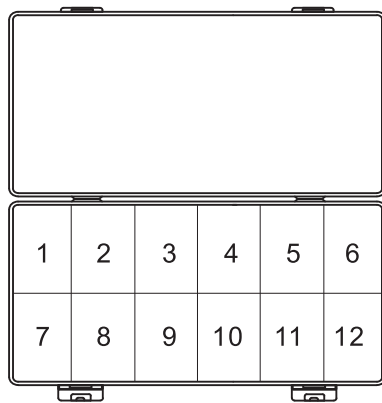


Data Sheet

Insulated Male and Female Crimp Disconnecter Pair Set

Typ. T1904C071

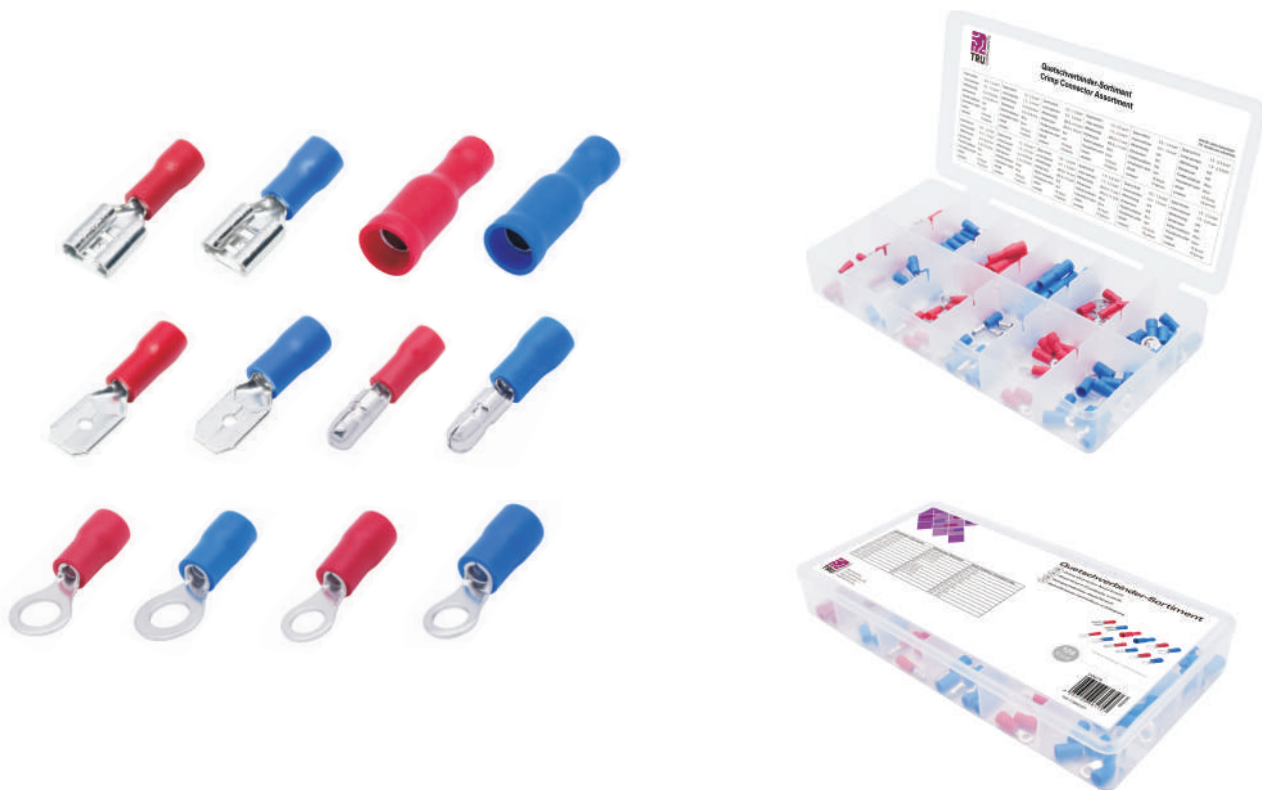

Section	Dimension (mm)	Wire range	Color	Contents
1	6.3 x 0.8	0.5-1.5 mm ²	Red	10pcs
2	6.3 x 0.8	1.5-2.5 mm ²	Blue	10pcs
3	Ø4.0 x 10	0.5-1.5 mm ²	Red	10pcs
4	Ø4.0 x 11	1.5-2.5 mm ²	Blue	10pcs
5	M5	0.5-1.5 mm ²	Red	10pcs
6	M5	1.5-2.5 mm ²	Blue	10pcs
7	6.3 x 0.8	0.5-1.5 mm ²	Red	10pcs
8	6.3 x 0.8	1.5-2.5 mm ²	Blue	10pcs
9	Ø4.0 x 10	0.5-1.5 mm ²	Red	10pcs
10	Ø4.0 x 10	1.5-2.5 mm ²	Blue	10pcs
11	M4	0.5-1.5 mm ²	Red	10pcs
12	M4	1.5-2.5 mm ²	Blue	10pcs