


# Data Sheet

## Insulated Crimp Butt Connector Set



Insulator material: Vinyl  
 Terminal material: Copper  
 Working Temperature: 75°C max.  
 Rating voltage: 600 V/AC max.  
 Rating current:  
 Red - 9 Amp. max.  
 Blue - 15 Amp. max.  
 Yellow - 20 Amp. max.

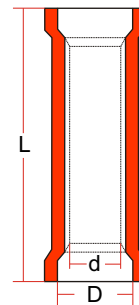

Type	Dimension(mm)			Wire range	Color	Contents
	ød	øD	L			
T1904C066	1.7	4.0	24.5	0.5-1.5 mm <sup>2</sup> 22-16 AWG	Red	50pcs
T1904C067	2.3	4.5	24.5	1.5-2.5 mm <sup>2</sup> 16-14 AWG	Blue	50pcs
T1904C123	3.4	6.5	26.0	4.0-6.0 mm <sup>2</sup> 12-10 AWG	Yellow	25pcs