


Data Sheet

Insulated Crimp Fork Terminal Connector Set



Insulator material: Vinyl
 Terminal material: Copper
 Working Temperature: 75°C max.
 Rating voltage: 600 V/AC max.
 Rating current:
 Red - 9 Amp. max.
 Blue - 15 Amp. max.
 Yellow - 20 Amp. max.

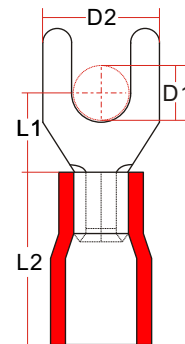

Type	Dimension(mm)				Wire range	Color	Contents
	øD1	øD2	L1	L2			
T1904C064	5.3	9.5	6.5	10	0.5-1.5 mm ² 22-16 AWG	Red	25pcs
T1904C065	5.3	8.0	6.5	11	1.5-2.5 mm ² 16-14 AWG	Blue	25pcs
T1904C122	5.3	9.5	8.0	13	4.0-6.0 mm ² 12-10 AWG	Yellow	15pcs