

Features

- Suitable for IT and Audio/Video Equipment
- Compliant to DoE 2016 (Level VI)
- ErP Stage 2, NRCan & GEMS Level VI
- No Load Power Consumption < 0.1 W
- Regulated Output with Low Ripple Noise
- 1 Year Warranty



Marks / Approvals





Specifications

Product similar to photo, variations possible.

	MODEL	Voltage	Min. Load	Max. Load	Max. Power
	ATS 060T-W120E	12 V	0.0 A	5.00 A	60 W
	ATS 060T-W150E	15 V	0.0 A	4.00 A	60 W
	ATS 060T-W180E	18 V	0.0 A	3.33 A	60 W
	ATS 060T-W190E	19 V	0.0 A	3.15 A	60 W
	ATS 060T-W240E	24 V	0.0 A	2.50 A	60 W
	ATS 060T-W300E	30 V	0.0 A	2.00 A	60 W
	ATS 060T-W480E	48 V	0.0 A	1.25 A	60 W
INPUT	<i>Voltage</i>	AC 100 V – 240 V			
	<i>Frequency</i>	50 Hz - 60 Hz			
	<i>Current</i>	1.50 A max.			
	<i>Protection</i>	Internal Primary Current Fuse, Inrush Limiting			
OUTPUT	<i>Load Regulation</i>	± 5 % (typical)			
	<i>Ripple</i>	1 % – 2 % V p-p max. for output voltage at full load			
	<i>Transient Response</i>	0.5 ms for 50 % load change typical			
	<i>Leakage Current</i>	0.25 mA max.			
	<i>Protection</i>	Short circuit Protection ▪ Over Voltage Protection ▪ Over Current Protection			
OTHERS	<i>Cooling</i>	Convection			
	<i>Efficiency</i>	DoE Level VI ▪ Energy Star ▪ ErP Stage 2 ▪ NRCan & GEMS Level VI Certified			
	<i>Holdup Time</i>	10 ms at full load			
	<i>Dielectric Withstand</i>	AC 3000 V Primary – Secondary			
	<i>MTBF</i>	300,000 calculated hours at 25 °C by telcordia SR-332			
ENVIRONMENT	<i>Temperature</i>	Operating: 0 °C – 40 °C / Storage: -20 °C – 80 °C			
	<i>Humidity</i>	Operating: 20 % RH – 80 % RH / Storage: 10 % RH – 90 % RH			
CONNECTION	<i>Cable</i>	Black UL 1185 18 AWG wire + plug; Length: 1500 mm			
	<i>Plug</i>	2.1 x 5.5 x 11 mm (tuning fork & cannellure); center positive			
EMI Conduction & Radiation	Compliance to EN 55022 Class B				
Harmonic Current	Compliance to EN 61000-3-2, -3				
EMS Immunity	Compliance to IEC 61000-1-2, -3, -4, -5, -6, -8, -11				
Safety	CE ▪ IEC 62368-1 ▪ EN 62368-1 ▪ IEC 60950-1 ▪ EN 60950-1				
Case Dimensions	95 mm × 54.4 mm × 35.5 mm (Europlug version)				
Weight	275 g				

Specifications subject to change without notice

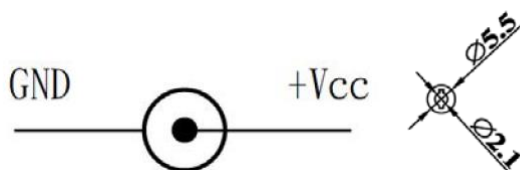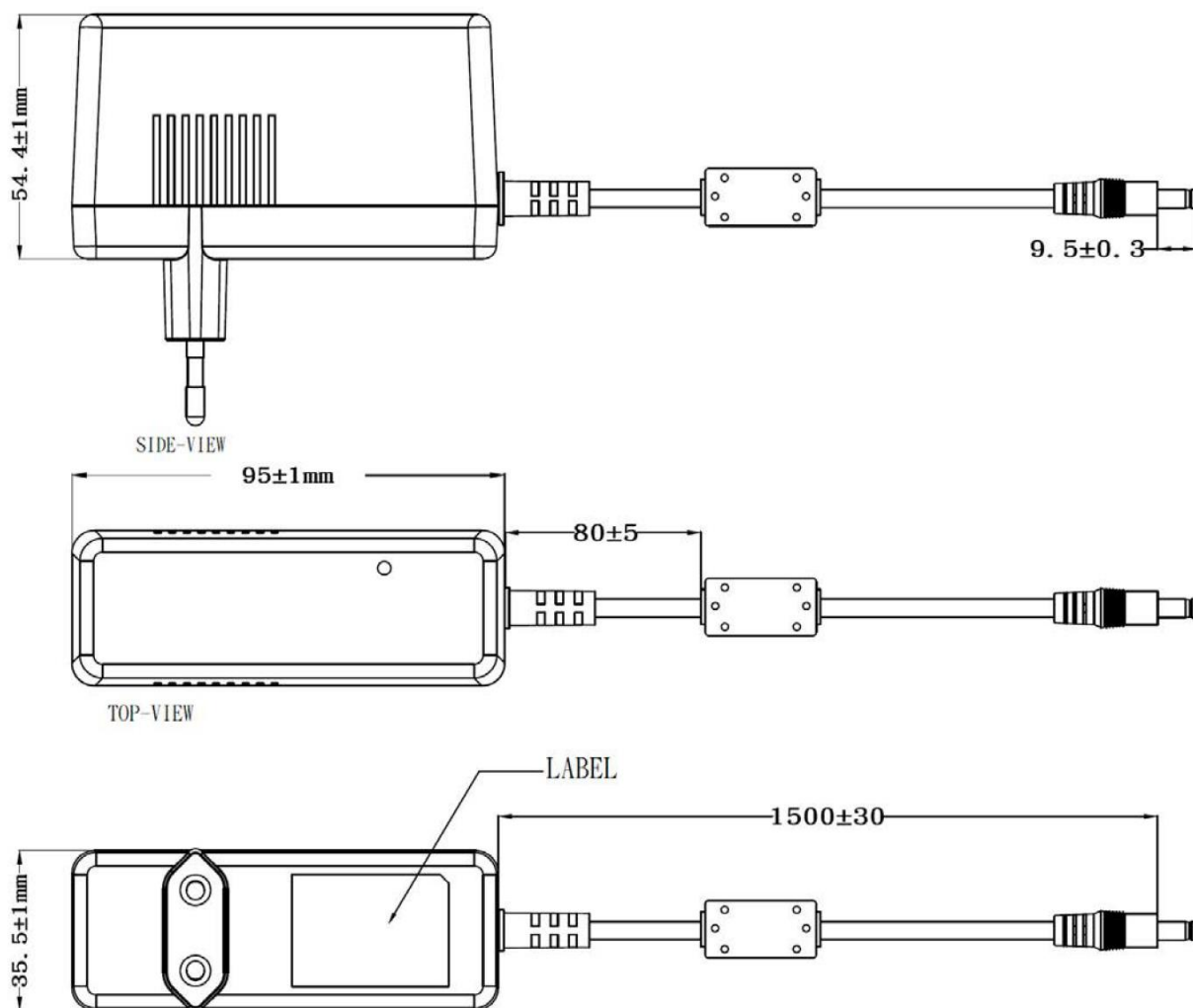

300%

ADAPTER TECH.
AC ADAPTER**MODEL : ATS060T-W240E****INPUT : 100-240V ~ 50-60Hz 1.5A MAX.****OUTPUT : 24V $\square$ 2.5A****LPS****CAUTION : Risk of electric Shock,
dry location use only.****FOR INDOOR USE ONLY****EFFICIENCY LEVEL VI**

Importer:
Dehner Elektronik GmbH
Untere Bein 3
65375 Oestrich-Winkel
Deutschland

Manufacturer:
Adapter Technology Co., Ltd
6F-9, No.258, Liancheng Rd.,
Zhonghe Dist., New Taipei City 235
Taiwan

**RoHS**

D/C:1750
MADE IN CHINA
ID NO. X
XXX