


Item no.: 2111258 / 2111259 / 2111261 / 2111256
2111257 / 2111262 / 2111260 / 2111267

Data Sheet

4:1 / 6:1 Heat Shrinking Tube Pack

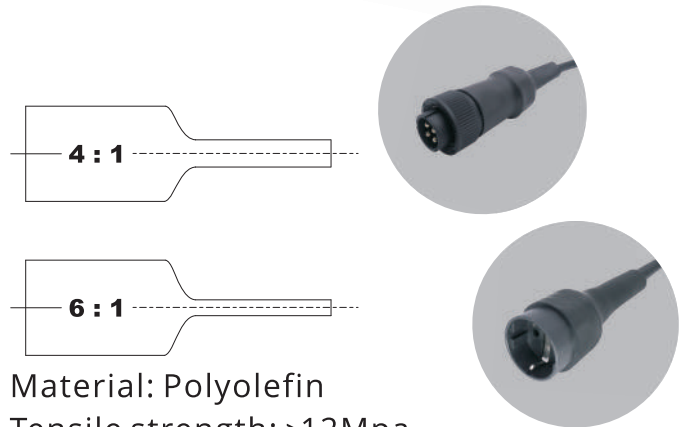

Material: Polyolefin
Tensile strength: $\geq 12\text{Mpa}$
Withstand voltage: $\geq 20\text{kv}/60\text{s}$
Volume resistance: $\geq 10^{12}\Omega/\text{cm}$
Flammability: VW-1
Operating Temperature: $-45 \sim 125^\circ\text{C}$
Minimum shrink temperature: 125°C
Full recovery temperature: 200°C

Typ.	Shrinking Ratio	Before shrink(ømm) Inner dia. (min.)	After shrink(ømm) I.D. (max.) W.T (min.)		Length	Contents
T1904CA043	4 : 1	8.0	2.0	1.2	200 mm	3 pc
T1904CA044	4 : 1	12.0	3.0	2.3	200 mm	3 pc
T1904CA045	4 : 1	20.0	5.0	2.5	200 mm	2 pc
T1904CA046	4 : 1	32.0	8.0	2.5	200 mm	1 pc
T1904CA047	6 : 1	19.0	3.2	3.2	200 mm	2 pc
T1904CA048	6 : 1	33.0	5.5	3.4	200 mm	1 pc
T1904CA049	6 : 1	45.0	7.4	3.6	200 mm	1 pc
T1904CA050	6 : 1	51.0	8.3	4.8	200 mm	1 pc