






I3T EOS

DUAL-OUTPUT SLIM EDC FLASHLIGHT

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
180 lumens	16 hours	60 meters

*This information is for market reference only. Please do not make it public.



I3T EOS

DUAL-OUTPUT SLIM EDC FLASHLIGHT



MARKET APPLICATIONS:

Outdoors
Home

UPC:

6926540908467

DESCRIPTION





The I3T EOS is a slim tail switch flashlight powered by a single AAA battery with a max output of 180 lumens. It is equipped with an excellent LED paired with a TIR optic lens producing a soft and balanced beam. It is also equipped with a dual direction pocket clip for multiple carrying options such as a pocket or backpack strap. The I3T is an incredibly convenient illumination experience to take with you everywhere.



FEATURES

- Powered by a convenient and widely available single AAA battery producing an output of 180 lumens.
- Double helix body knurling for unique style and solid grip.
- Super easy carry: Barely know it is there with its lightweight and slender form factor. The dual direction pocket clip makes the I3T even more convenient for carrying in a pocket or attaching to a hat or strap.
- Highly integrated tail switch: The user can operate momentary on and quick mode shifting (5/180 lumens) all through a convenient tail switch.
- The I3T is equipped with a TIR optic lens producing a soft and balanced beam for comfortable use.

OUTPUT

FL1 STANDARD	MODE 1	MODE 2
	180 lumens	5 lumens
	21 minutes	16 hours
	60 meters	12 meters
	900 cd	36 cd

*The above data are test results retrieved according to ANSI NEMA FL 1-2009 standards.

LIGHT SOURCE

Philips LUXEON TX CW LED

DIMENSIONS

Length: 3.5in/89mm
Head Diameter: 0.59in/15mm
Body Diameter: 0.59in/15mm

WEIGHT

1.45oz/41g (with battery and pocket clip)

BODY MATERIAL

Aluminum Alloy

POWERED BY

1 x 1.5V AAA Alkaline Battery (included)
1 x 1.5V AAA NiMH/Lithium Battery (compatible)
Note: NOT compatible with Li-ion Battery


WARRANTY

Olight's 5 Year Warranty
Visit: <https://olightworld.com/olight-warranty>

STANDARD ACCESSORIES

1 x 1.5V AAA Alkaline battery

WATERPROOF IPX8

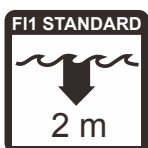

DROP TEST



COMPLIANCE

