




SEEKER 2 PRO

L-DOCK CHARGING, ON-THE-GO LED FLASHLIGHT

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
3,200 lumens	12 days	250 meters



SEEKER 2 PRO

L-DOCK CHARGING, ON-THE-GO LED FLASHLIGHT



MARKET APPLICATIONS

Household & Outdoors & Law Enforcement

UPC: 692654091632 5


DESCRIPTION

The Seeker 2 pro is a powerful, rechargeable side-switch LED flashlight. Powered by a single, maximum capacity, (5000mAh) 21700 customized lithium rechargeable battery, that helps this light deliver a maximum output of 3200 lumens. It uses high-quality LEDs paired with a TIR optic lens, providing a perfect medium and close-range illumination experience. The Seeker 2 pro features a large side switch located near the head of the light for comfortable thumb operation and indicators on both sides of the switch clearly display the battery power and brightness level. With milled finger grooves and dermatoglyphic silicone, the Seeker 2 pro is ergonomically designed to be extremely comfortable and provides a non-slip grip.

The Seeker 2 pro includes a 3.9 ft long 1A magnetic USB cable (The MCC1AL is compatible with OLIGHT S, M, and H series). The provided L-dock can be attached to or fixed on a wall close to a power source for quick and easy access. Compatible with most USB power sources, the magnetic charging cable is convenient to use, making it an ideal illumination kit to be used at home, outdoors, or while on duty.



Seeker 2 pro Runtime

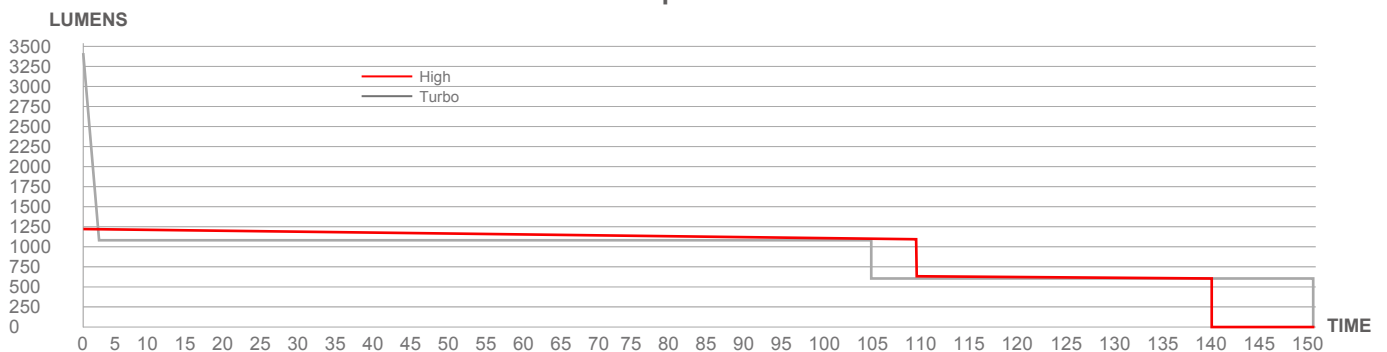

SEEKER 2 PRO

L-DOCK CHARGING, ON-THE-GO LED FLASHLIGHT



FEATURES

- Compact size with powerful performance: incredibly delivers a maximum output of 3,200 lumens and a long beam distance of 250 meters, providing you a new flagship-level illumination experience.
- Convenient L-dock included: can be attached to or fixed (3M tape included) on a wall or table indoors that is close to a power source, providing a dedicated charging location for your Seeker 2 pro.
- Visual display indicators on both sides of the switch: the four indicators on the right side clearly display the battery level and the four on the left side display the brightness level.
- Milled finger grooves and dermatoglyphic silicone are used on the surface of the holding position, making it soft and anti-slip.
- Customized high capacity 21700 lithium rechargeable battery: currently the highest 5000mAh battery in its size for great runtimes.

OUTPUT

FL1 STANDARD	Mode 1	Mode 2	Mode 3	Mode 4	Mode 5
	3,200 ± 600 lumens	1,200 ± 600 lumens	300 lumens	50 lumens	5 lumens
	2+150 minutes	110+30 minutes	9.5 hours	50 hours	12 days
	250 meters	150 meters	70 meters	30 meters	10 meters
	15,600 _{cd}				

LIGHT SOURCE

3 LEDs (CCT: 5700-6500K)

DIMENSIONS

Length: 5.04in/128mm
Head Diameter: 1.38in/35mm
Body Diameter: 1.10in/28mm

WEIGHT

6.98oz/198g (including battery)

WATERPROOF IPX8



DROP TEST



COMPLIANCE



The above data are test results retrieved according to ANSI NEMA FL 1-2009 standards.

BODY MATERIAL

AL6061-T6 Aluminum Alloy

BATTERY SOURCE

Customized rechargeable 21700, 5000mAh
3.6v Battery

IN THE BOX

Flashlight (Battery included)×1
MCC1AL Magnetic Charging Cable ×1
Self-Adhesive Ply-Yarn Drill ×2
L-dock Charging ×1 Set (includes holder, adhesive,and screw)
Holster ×1
Cleaning Cloth ×1
User Manual ×1