

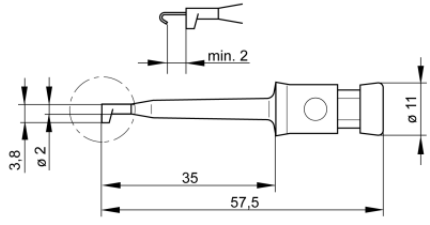


## Clamp-type test probe

### KLEPS 2



Product	KLEPS 2
description	Miniature clamp-type test probe with solder connection. Gold-plated sprung bronze contact hook for wires up to a maximum diameter of 2 mm. Remove actuator button for soldering, when cable is connected, press back on until it engages.
operating instruction	BA202
article-no. / *colour	9314671xx <div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;">  00 black         </div> <div style="text-align: center;">  01 red         </div> </div> <div style="text-align: right; border: 1px solid black; padding: 2px; width: fit-content; margin-top: 10px;">Au</div>
drawing	
technical data	
connection	solder connection
rated voltage <sup>(1)</sup>	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O <sup>(3)</sup>
rated current <sup>(1)</sup> (consider derating curve)	6 A
housing material	PA
temperature range acc. To IEC61010 <sup>(2)</sup>	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
clamp type	contact hook, gold plated
clamping range	max. Ø 2 mm

2 mm system

standard	IEC 61010
----------	-----------

<sup>(1)</sup> for normal environmental conditions -5°C to +40°C

<sup>(2)</sup> contact the manufacturer for applications at deviating temperature ranges

<sup>(3)</sup> without rated measurement category, for other circuits that are not directly connected to mains  
stand: 10.01.2019