


Crocodile clips

AGS 20

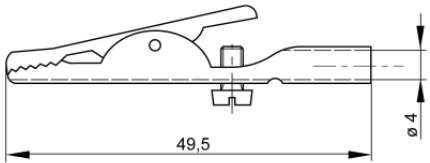

Product	AGS 20
description	Nickel-plated steel alligator clip. Clamping range up to a maximum bolt diameter 5 mm. 4 mm diameter socket connection, connection possible by terminal screw and solder connection.
Articlenummer	603006001 Ni
drawing	
	
technical data	
connection	unsprung socket 4 mm, solder connection, screw terminal
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	4 A
material socket	steel, nickel plated
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +100 °C
clamping range	5 mm
standard	IEC 61010

4 mm system

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 22.06.2018