

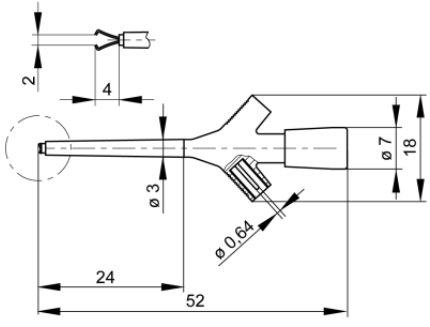


Clamp-type test probe

KLEPS 3 ST



Product	KLEPS 3 ST
description	Miniature clamp-type test probe with rotating grip jaws. Suitable for very thin wires and densely packed contacts. Connects with MKL... and MAL...
operating instruction	BA002
article-no. / *colour	9735921xx <div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;">  00 black </div> <div style="text-align: center;">  01 red </div> </div>
drawing	
technical data	
connection	unsprung pin Ø 0.64 mm
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	2 A
material plug	brass, gold plated
housing material	PBT
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamp type	rotating grip jaws, tin plated
clamping range	2 mm

0.64 mm system

standard	IEC 61010
----------	-----------

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 10.01.2019