

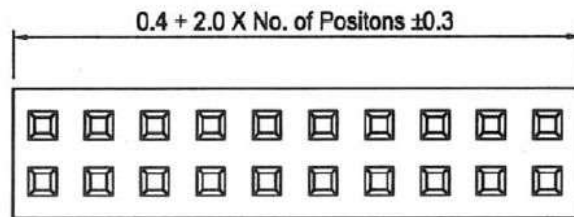
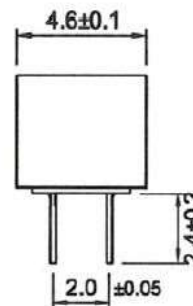


## Datenblatt

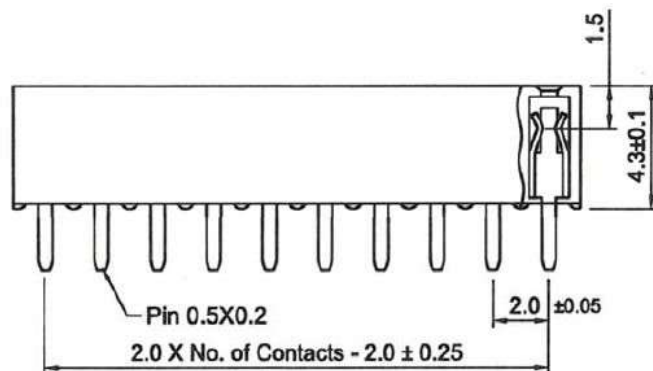

Recommended  
P.C. Board Hole Layout

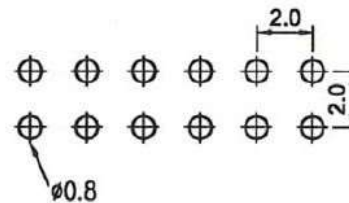

### Specifications

Current Rating : 2 Amps

Insulator Resistance : 1000 Megohms min.

Contact Resistance : 20 m ohms max.

Dielectric Withstanding : AC 500V

Operating Temperature : -40°C ~ +105°C

Contact Material : Phosphor Bronze

Insulator Material : Polyester, UL 94V-0 Nylon-6T

Contact Plated : See Option

Standard: Full Gold Flash