


Datenblatt

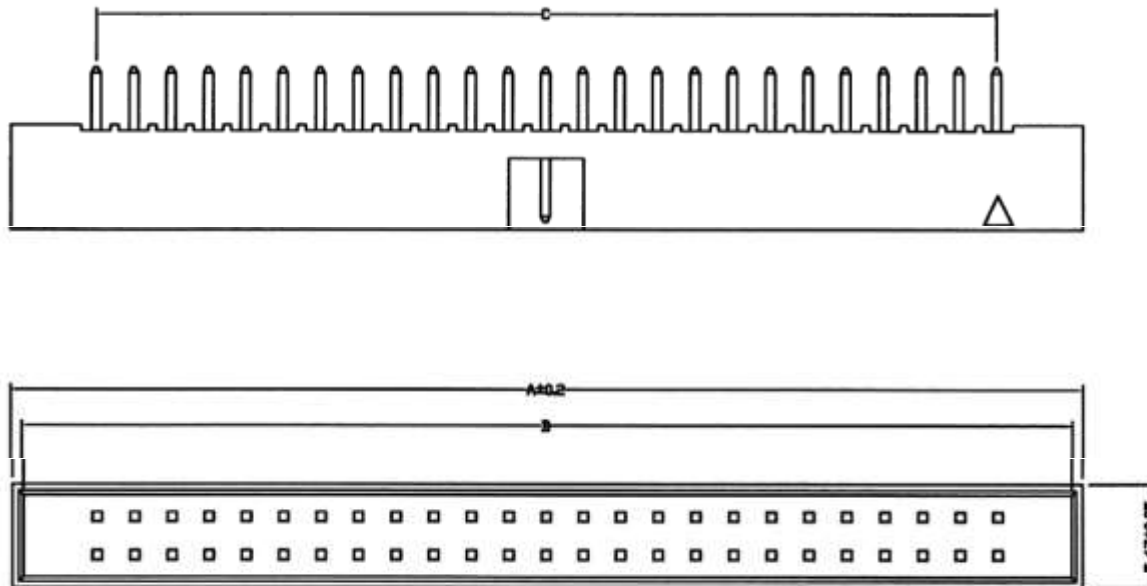

SPECIFICATIONS:

Material:

Insulator: LYLDN-6T

Insulator color: Black

Contacts: Brass

Contact Plating:

Gold Flash over Nickel underplate overall

Electrical:

Operating voltage: 250 VAC max

Current rating: 3 Amp max

Contact resistance: 20 mohms max

Insulation resistance: 5,000 Mohms min

Dielectric withstanding voltage: 1,000 VAC / minute

Mechanical:

Mating durability: 500 cycles min


Temperature Rating:

Operating temperatures: -40° to +105°

Environmental:

Lead free, RoHS compliant

Recommended soldering temp: 260° for 5 second

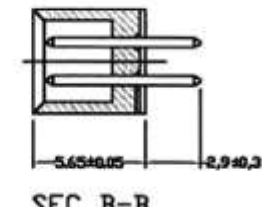

RoHS COMPLIANT