

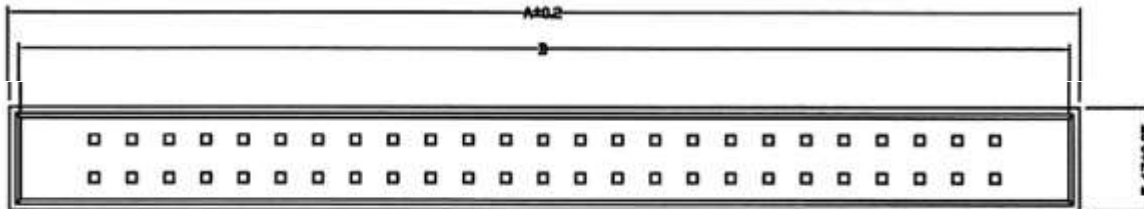


# Datenblatt

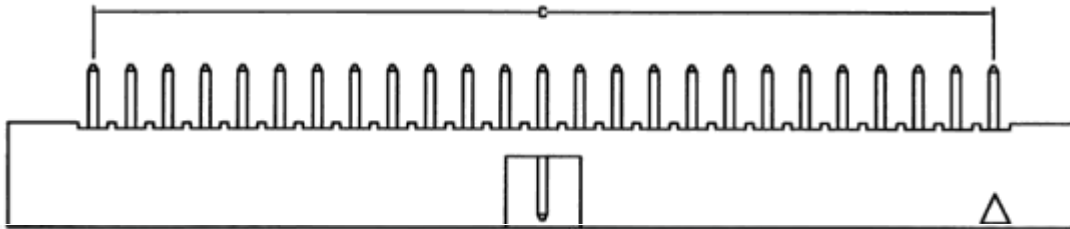

### SPECIFICATIONS:

- Material:
- Insulator: LYLDN-6T
- Insulator color: Black
- Contacts: Brass
- Contact Plating:
- Gold Flash over Nickel underplate overall
- Electrical:
- Operating voltage: 250 VAC max
- Current rating: 3 Amp max
- Contact resistance: 20 mohms max
- Insulation resistance: 5,000 Mohms min
- Dielectric withstanding voltage: 1,000 VAC / minute
- Mechanical:
- Mating durability: 500 cycles min
- Temperature Rating:
- Operating temperatures: -40° to +105°
- Environmental:
- Lead free, RoHS compliant
- Recommended soldering temp: 260° for 5 second

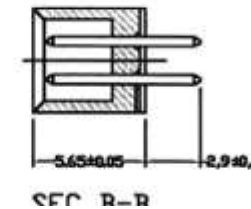

RoHS COMPLIANT