
 


Datenblatt

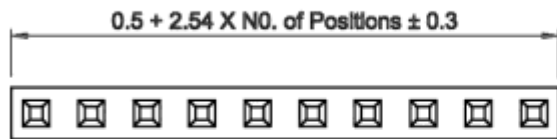

Recommended P.C. Board Hole Layout



Specifications

Current Rating : 3 Amps

Insulator Resistance : 1000 Megohms min.

Contact Resistance : 20 m ohms max.

Dielectric Withstanding : AC 600V

Operating Temperature : -40°C ~ +105°C

Contact Material : Phosphor Bronze

Insulator Material : Polyester, UL 94V-0 P.B.T.

Contact Plated : See Option

Standard: Full Gold Flash

