


Datenblatt

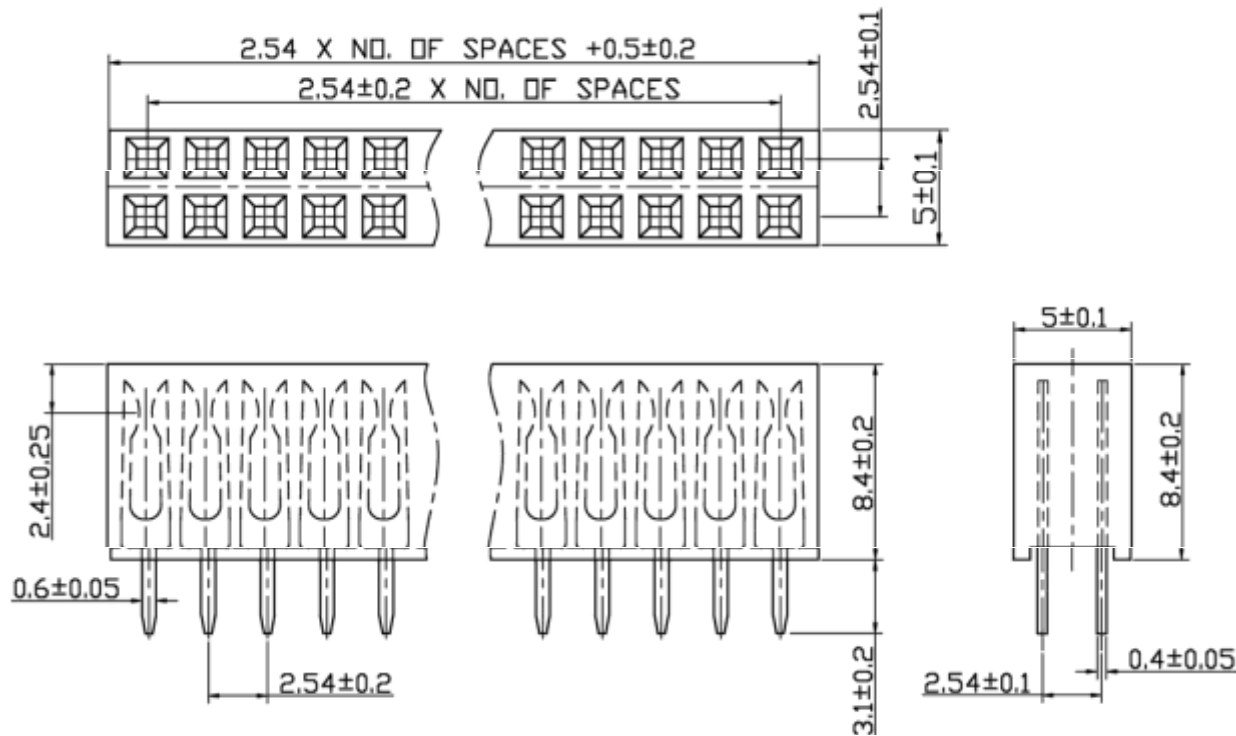

SPECIFICATIONS

Current Rating: 3 Amp

Insulation Resistance: 1000M Ω Min

Dielectric Withstanding: 600V AC/DC

Contact Resistance: 20m Ω Max.

Operating Temperature: -40°C to +105°C

MATERIALS

Contact Material: Phosphor Bronze

Insulation Material: Polyester, UL 94V-0

P.B.T or Nylon-6T

Contact Plating: Full Gold, Full Tin, Selective Plated

Standard: Gold Flash all Over Nickel

RoHS COMPLIANT