



Datenblatt

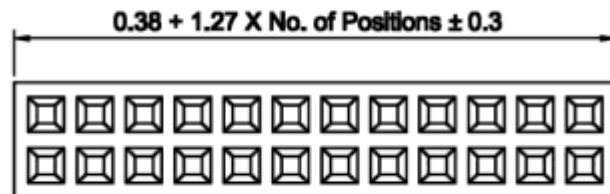

Recommended
P.C. Board Hole Layout

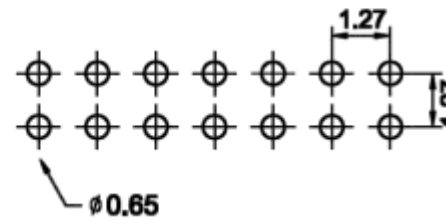

Specifications

Current Rating : 1 Amp

Insulator Resistance : 1000 Megohms min.

Contact Resistance : 20 m ohms max.

Dielectric Withstanding : AC 300V



Operating Temperature : -40°C ~ +105°C

Contact Material : Phosphor Bronze

Insulator Material : Polyester, UL 94V-0 LCP

Contact Plated : See Option

Standard: Full Gold Flash

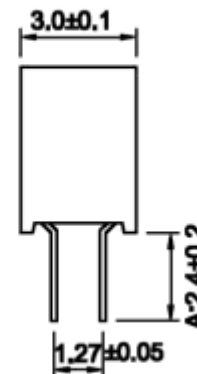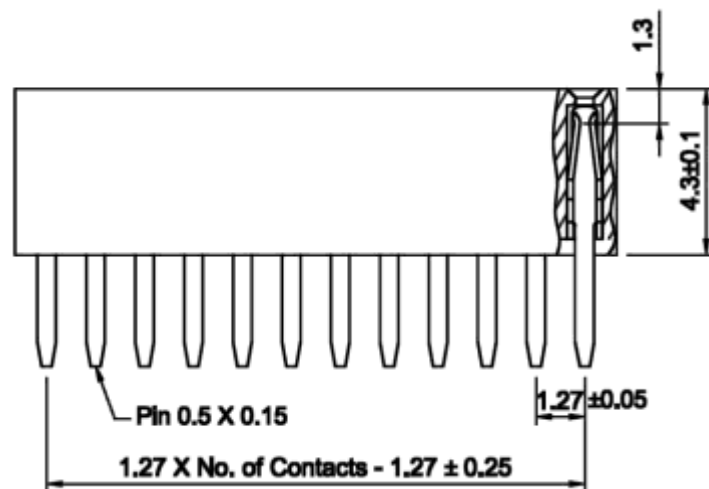

RoHS COMPLIANT