

Connector - SACC-MSX-8QO SH ETH SCO - 1411043

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Connector, Ethernet CAT6_A (10 Gbps), 8-position, halogen-free, shielded, Plug straight M12 SPEEDCON, X-coded, Insulation displacement connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 5 mm ... 9.7 mm

Your advantages

- Safe use in the field, thanks to a high degree of protection
- Flexible: connectors for on-site assembly
- Insulation displacement connection: innovative and time-saving assembly without stripping the single wire
- Save time, thanks to installation with SPEEDCON fast locking system
- Reliable signal transmission - 360° shielding in environments with electromagnetic interference



Ethernet

Key commercial data

package_quantity	1
GTIN	4046356997935

Technical data

Dimensions

Wrench size, union nut	15 mm
Diameter housing	19 mm
Length	58 mm
External cable diameter	5 mm ... 9.7 mm
Stripping length of the sheath	≥ 80 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 85 °C (Plug / socket)
Ambient temperature (assembly)	-5 °C ... 50 °C
Degree of protection	IP65
	IP67

General

Rated current at 40 °C	0.5 A
Rated voltage	48 V AC
	60 V DC
Number of positions	8

Connector - SACC-MSX-8QO SH ETH SCO - 1411043

Technical data

General

Insulation resistance	≥ 100 MΩ
Coding	X - data
Standards/regulations	M12 connector IEC 61076-2-109
	Shock, vibration EN 50155:2001
Signal type/category	Ethernet CAT6 _A (IEC 11801), 10 Gbps
Status display	No
Overvoltage category	II
Degree of pollution	3
Connection method	Insulation displacement connection
Conductor cross section	0.14 mm ² ... 0.34 mm ² (flexible)
	0.14 mm ² ... 0.34 mm ² (solid)
Conductor cross section AWG	26 ... 22 (flexible)
	26 ... 22 (solid)
Wire diameter including insulation	0.75 mm ... 2 mm
Frequency of connections between conductors of the same cross section	10
Wire insulation material	PVC / PE / PP / rubber
Structure of individual litz in acc. with VDE 0295 / smallest wire diameter	Class 2-6
Insertion/withdrawal cycles	≥ 100
Torque	M12 knurl
	5 Nm (Pressure nut)

Material

Flammability rating according to UL 94	V0
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	PA 6.6
Material of grip body	Zinc die-cast, nickel-plated
Material, knurls	Zinc die-cast, nickel-plated
Sealing material	NBR
Standards/regulations	PA 6.6: Fire protection in rail vehicles - requirement sets R22, R23, R24, and R26 acc. to DIN EN 45545-2 (Risk level HL1 - HL3)

Standards and Regulations

Standard designation	M12 connector
Standards/regulations	IEC 61076-2-109
Standard designation	Shock, vibration
Standards/regulations	EN 50155:2001
Flammability rating according to UL 94	V0

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
------------	---

Connector - SACC-MSX-8QO SH ETH SCO - 1411043

Technical data

Environmental Product Compliance

	No hazardous substances above threshold values
--	--

Classifications

eCl@ss

eCl@ss 5.1	27143400
eCl@ss 6.0	27279200
eCl@ss 7.0	27440104
eCl@ss 8.0	27440104
eCl@ss 9.0	27440102

ETIM

ETIM 5.0	EC002635
ETIM 6.0	EC002635
ETIM 7.0	EC002635

Approvals

EAC /

Approval details

EAC ENEC

Accessories

Torque tool

TSD 04 SAC - 1208429



TSD-M 1,2NM - 1212224



Connector - SACC-MSX-8QO SH ETH SCO - 1411043

Accessories

Screwdriver tools

SACC BIT M12-D20 - 1208445



TSD-M SAC-BIT ADAPTER - 1212600



Protective cap

PROT-M12 FS-PA-CHAIN - 1430873



Stripping tool

WIREFOX-D 40 - 1212161



Electronics pliers

MICROFOX-SB - 1212489



Connector - SACC-MSX-8QO SH ETH SCO - 1411043

Accessories

Accessories

VS-08-RJ45-FOLIEN-SET - 1417184

 


VS-CABLE-STRIP-VARIO - 1657407




Drawings

Functional drawing




Dimensional drawing

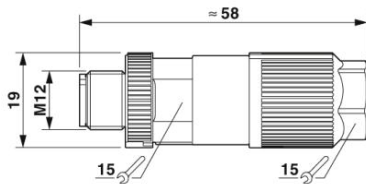

Plug, M12 x 1, straight, shielded

Connector - SACC-MSX-8QO SH ETH SCO - 1411043

Schematic diagram

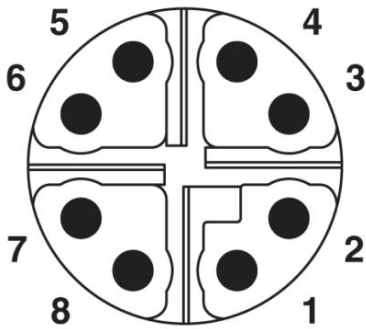

Pin assignment M12 plug, 8-pos., view plug side

Phoenix Contact 2019 © - all rights reserved
<http://www.phoenixcontact.com>