


Data Sheet

Twincable-ferrules-Set (DIN 46228)



Insulator material: PVC
Terminal material: Tinned Copper
Working Temperature: 75°C max.
Rating voltage: 600 V/AC max.

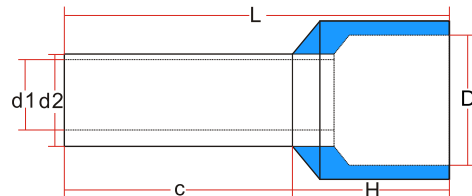

Type	Dimension(mm)						Wire range	Color	Contents
	H	c	L	ød1	ød2	øD			
T1906C152	6.5	8.0	14.5	1.5	1.8	5.0	0.5 mm ²	White	100pcs
T1906C153	6.7	8.0	14.7	1.8	2.1	5.5	0.75 mm ²	Grey	100pcs
T1906C154	7.1	8.0	15.1	2.0	2.3	5.5	1.0 mm ²	Red	100pcs
T1906C155	7.5	8.0	15.5	2.3	2.6	6.4	1.5 mm ²	Black	100pcs
T1906C156	8.5	10.0	18.5	2.2	2.6	8.0	2.5 mm ²	Blue	50pcs
T1906C157	11.1	12.0	23.1	3.8	4.2	8.8	4.0 mm ²	Grey	50pcs
T1906C158	9.3	14.0	23.3	4.9	5.3	9.5	6.0 mm ²	Yellow	25pcs
T1906C159	12.5	14.0	26.5	6.5	6.9	12.5	10.0 mm ²	Red	25pcs