 
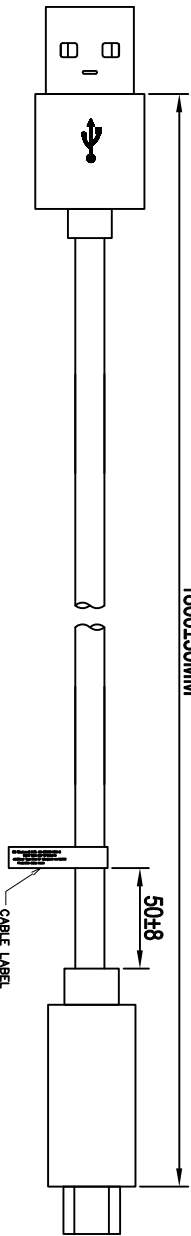
 
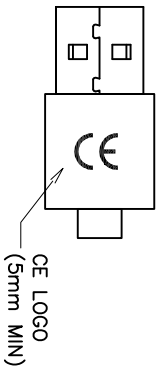
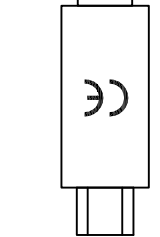
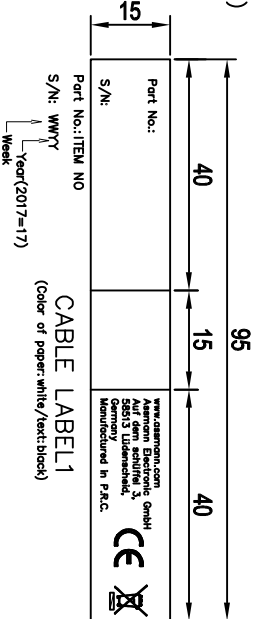
 
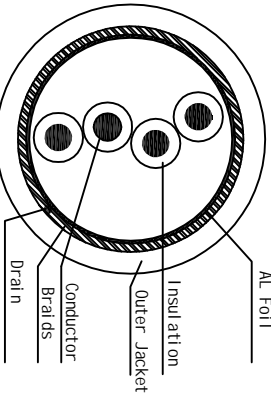


	1	2	3	4	5	6	7												
A	USB2. 0 /AM		ROHS & REACH Compliant				A												
B						TYPE C/M 	B												
C							C												
D			Part No.: ITEM NO S/N: WMYT Year(2017=17) Week	CABLE LABEL1 (Color of paper:white/ver:black)	PIN OUT P1 _____ P2		D												
E	NOTE: 1. CABLE: 24AWG*2C CU+28AWG*1P CU+AL MYLAR+48braids OD: 4.5MM JACKET COLOR: BLACK CABLE PRINT: Assmann Electronic GmbH 58513 Lüdenscheid, Germany 2. LENGTH: 1.8M 3. CONNECTOR: TYPE C/M *1PCS, USB2. 0 /AM *1PCS (BLACK INSULATION) (SHELL NICKEL) 4. MOLD: ASSY TYPE--MOLDING TYPE. 5. OPEN/SHORT TEST: 100% TEST.				1 _____ A4 4 _____ A1 2 _____ A7 3 _____ A6 SHELL _____ SHELL		E												
F	6. ALL MUST BE ROHS COMPLIANT. A.100% OPEN,SHORT&INTERMITTANCE TEST. B.CONDUCTOR RESISTANCE:3ohms MAX: C.INSULATION RESISTANCE:5M Min/,10ms:	Cross Section:					F												
G				<table border="1"> <tr> <td>Drawn by</td> <td>2022/12/12</td> <td>Date</td> <td>Name</td> </tr> <tr> <td>Checked by</td> <td></td> <td></td> <td></td> </tr> <tr> <td>Approved by</td> <td></td> <td></td> <td></td> </tr> </table>	Drawn by	2022/12/12	Date	Name	Checked by				Approved by				Part No. AK-300154-018-S EAN:4016032455240	Title USB TYPE C connection cable	G
Drawn by	2022/12/12	Date	Name																
Checked by																			
Approved by																			
H	1	2	3	4	ASSMANN Electronic GmbH Scale N/A Unit MM Sheet 1 / 2	87363	H												

Package Details

ROHS & REACH Compliant

Single Cable


PN	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)
AK-300154-018-S	1.8M	120±10MM	DIGITUS Polybag	170*250mm	0.06kg

Inner Packing Unit



PN	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)
AK-300154-018-S	1.8M	10PCS	Polybag (Heat Sealed)	280*360mm	0.6kg

CARTON DETAILS


PN	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)
AK-300154-018-S	1.8M	200PCS	450*340*280mm	11.8kg	12.8kg

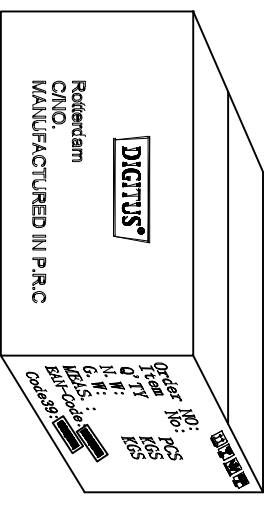

* "ROTTERDAM" is for Sea Freight shipment
 * "COLOGNE" is for Air Freight shipment
 * "LUDENSCHIED" is for Fedex or UPS shipment

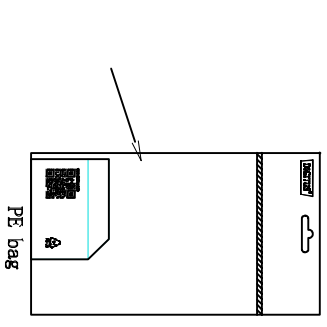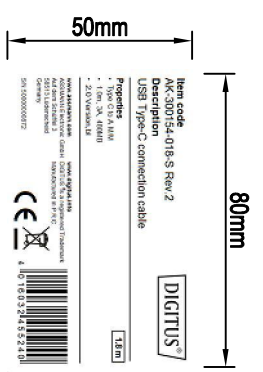

Inner Packing Unit
HEAT SEALED

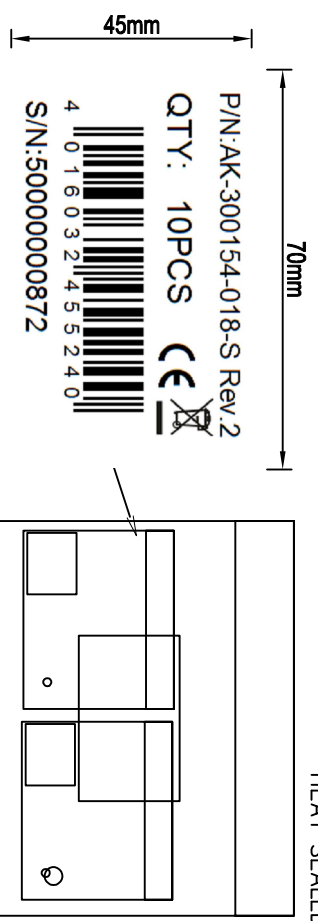

Drawn by	2022/12/12	Date	Name
Checked by			
Approved by			

ASSMANN
Electronic GmbH

87363

Part No.	AK-300154-018-S
EAN:4016032455240	
Title	USB TYPE C connection cable

Scale	N/A	Sheet	2 / 2
Unit	MM		

A	1	2	3	4	5	6	7
B	1	2	3	4	5	6	7
C	1	2	3	4	5	6	7
D	1	2	3	4	5	6	7
E	1	2	3	4	5	6	7
F	1	2	3	4	5	6	7
G	1	2	3	4	5	6	7
H	1	2	3	4	5	6	7