

The best experience
in cycling navigation



Cyclo™ 215 HC

AVAILABLE WITH FULL EUROPEAN MAPS



Wireless heart rate monitor, wheel and cadence sensor are included.



Easy and user friendly navigation

Large on-screen control buttons and simple menu structure



Full European cycle maps pre-installed

Pre-installed full European cycle maps, so you are ready to go right out of the box



Turn-by-turn instructions

Clear guidance with a sound alert to indicate every instruction



Cycling-related POIs

Quickly search for bike shops, emergency locations, food & drink and more



Desktop application

One tool to easily manage your device, download new routes and share your experiences



Long-life rechargeable batteries

Up to 10 hours performance



Surprise Me™-feature

Just choose your time or distance and the Mio Cyclo™ 215 HC will offer you 3 surprising routes to choose from



Where am I

In case of emergency, this function shows your current address, along with longitude and latitude.



Water resistant (IPX5)

Find your way in every weather



Measures your...

Speed, time, distance, calories burned and more



Integrated ANT+ sensor

Compatible wireless heart rate monitor and wheel and cadence sensor.

Meet the Mio Cyclo™ 215 HC: the easy-to-use bicycle navigation device for anyone who enjoys cycling. With full European cycle paths and road maps pre-installed, you are able to get started right out of the box. And thanks to the integrated ANT+, the included heart rate monitor and cadence sensor, you can measure your performance at all times.

The Mio Cyclo™ 215 HC allows you to navigate easily from point A to B or to follow your own preferred routes. If you choose to use the unique Surprise Me™-feature, the Mio Cyclo™ 215 HC will calculate three surprising bicycle routes based upon your entered time or distance. This is the ideal feature for anyone who has seen all the local routes and for those who like to be surprised in an unfamiliar region. This feature will continuously offer new bicycle routes, even if you always start from the same point.

The turn-by-turn navigation effortlessly guides you, indicating every instruction with a clear sound alert. With its large anti-glare 3,5" touch screen, the simple menu structure and clear on-screen buttons, the Mio Cyclo™ 215 HC offers you true ease of use.

The rugged waterproof casing (IPX5) ensures you can go cycling in any kind of weather, rain or shine. And with the long, rechargeable battery life of 10 hours, you can enjoy longer distances without having to worry about finding your way back home. Thanks to the pre-installed points of interests (POIs), such as bicycle shops, restaurants and emergency locations, you will always be able to locate some refreshments or a new tyre with ease.



Cyclo™ 215 HC




AVAILABLE WITH FULL EUROPEAN MAPS



Weight: 151 grams



Where Am I Function

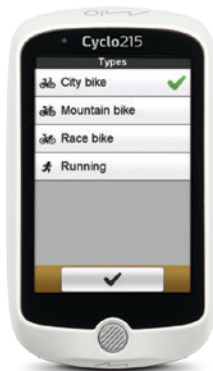

Profile - Bike Type



Surprise Me™



Tracks Menu

The Mio Cyclo™ 215 HC measures time, speed, distance, height, calorie consumption and more. With the desktop application, you are able to store your data, manage your route history and share your experiences with your friends. The easy-to-use tool allows you to download routes and enjoy new roads and areas others find interesting. The application is also your one-stop shop for managing your device and downloading map updates or latest product information.

The Mio Cyclo™ 215 HC is the ideal solution for anyone who enjoys cycling, wants true ease of use and is looking for perfect value for money.

The Mio Cyclo™ 215 HC comes with a built-in ANT+ sensor, allowing you to easily connect with a wireless heart rate monitor, wheel and cadence sensor. The wireless heart rate monitor and wheel and cadence sensors are already included to complete the package.

Box Content:



Check mio.com/cyclo for a store near you!

©2018 MiTAC Digital Technology Corp.
All trademarks are the property of their respective owners.
All specifications are subject to change without prior notice.

AVAILABLE WITH FULL EUROPEAN MAPS

EUROPE 38

AD • AT • BE • CH • DE • DK • ES • FL • FR • GB • GI • IE
IT • LI • LU • MC • MT • NL • NO • PT • SE • SM • VA
BG • CZ • HR • EE • GR • HU • LT • PL • RO • SK • SI • RS • TR • UA