

Mounting Accessories Spacer Bolts Metal

Brass, Inner / Inner Thread M3 AF 5.0



MATERIAL:

Material: copper alloy brass, nickel plated



HANDLING:

Packaging: bulk

TOLERANCE:

.X: ± 0.38

.XX: ± 0.25

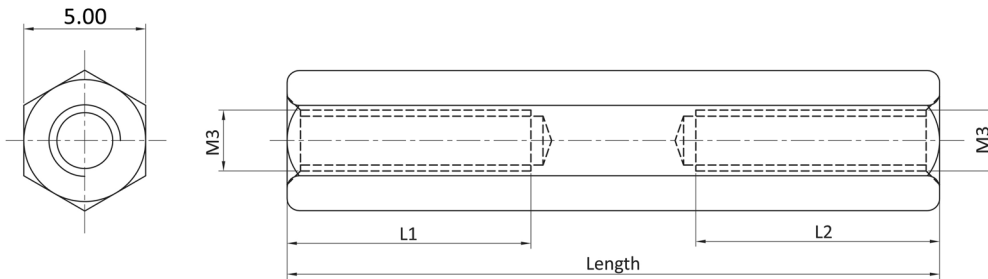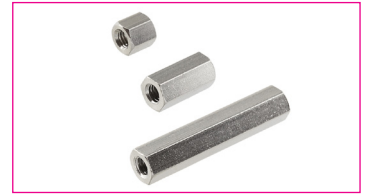

Dimensions

Length:	L1 (Inside Thread):	L2 (Inside Thread):
5	2.5	2.5
6	3	3
8	4	4
10	5	5
12	6	6
15	7.5	7.5
18	8	8
20	10	10
25	10	10
30	10	10
40	10	10

Order Information

Identifier:	Thread:	Length:	Version:	Width across flats:	Material:	Packing Unit:
D	3X	#	I	5	M	#
Spacer bolt	M3	05: 5 mm 06: 6 mm 08: 8 mm 10: 10 mm 12: 12 mm 15: 15 mm 18: 18 mm 20: 20 mm 25: 25 mm 30: 30 mm 40: 40 mm	inner / inner thread	5 AF	brass, nickel plated	H: 100 pieces T: 1000 pieces