

RT Pico



WX

RT Micro



WX



WT

RT Ultra




WX



 
	Soldering Iron: WXPP ○ / WXPP MS ●			Soldering Iron: WXMP ○ / WXMP MS ● / WMRP ○ / WMRP MS ●			Soldering Iron: WXUP MS ●		
	article		a / b (mm) (inch)	article		a / b (mm) (inch)	article		a / b (mm) (inch)
Conical 	RTP 001 C T0050103199 RTP 001 C MS T0050107399		0.1 / 0.004	RTM 001 C NW T005446299N RTM 001 C NW MS T0054462571N		0.1 / 0.004	RTU 004 C MS T0050104999		0.4 / 0.016
	RTP 001 C NW T0050103299 RTP 001 C MS NW T0050101499		0.1 / 0.004	RTM 002 C T0054460199N RTM 002 C MS T0054461499N		0.2 / 0.008	RTU 008 C MS T0050105099		0.8 / 0.031
	RTP 002 C T0050103399 RTP 002 C MS T0050101599		0.2 / 0.008	RTM 002 C L T0050100099 RTM 002 C L MS T0050100199		0.2 / 0.008	RTU 016 C MS T0050105199		1.6 / 0.063
	RTP 004 C T0050103499 RTP 004 C MS T0050101699		0.4 / 0.016	RTM 004 C X MS T0054463399N		0.4 / 0.016	RTU 004 C X MS T0050105299		0.4 / 0.016
	RTP 001 C X T0050103599 RTP 001 C X MS T0050101799		0.1 / 0.004	RTM 005 C X MS T0054463299N		0.5 / 0.019	RTU 008 C X MS T0050105399		0.8 / 0.031
	RTP 002 C X T0050103699 RTP 002 C X MS T0050101899		0.2 / 0.008	RTM 008 C T0054460299N RTM 008 C MS T0054461799N		0.8 / 0.031	RTU 016 C X MS T0050105499		1.6 / 0.063
Bevel Cut 	RTP 004 B T0050103799 RTP 004 B MS T0050101999		0.4 / 0.016	RTM 004 B T0050100299 RTM 004 B MS T0050100399		0.4 / 0.016	RTU 020 B MS T0050105599		2.0 / 0.079
	RTP 012 B T0050103899 RTP 012 B MS T0050102099		1.2 / 0.047	RTM 012 B T0054460699N RTM 012 B MS T0054461799N		1.2 / 0.047	RTU 035 B MS T0050105699		3.5 / 0.138
							RTU 050 B MS T0050105799		5.0 / 0.197
Chisel 	RTP 002 S T0050103999 RTP 002 S MS T0050102199		0.2 / 0.1 / 0.008 / 0.004	RTM 003 S NW T0054462699N RTM 003 S NW MS T0054462671N		0.3 / 0.1 / 0.012 / 0.004	RTU 015 S MS T0050105899		1.5 / 0.4 / 0.059 / 0.016
	RTP 002 S NW T0050104099 RTP 002 S NW MS T0050102299		0.2 / 0.1 / 0.008 / 0.004	RTM 004 S T0054461299N RTM 004 S MS T0054461599N		0.4 / 0.15 / 0.016 / 0.006	RTU 022 S MS T0050105999		2.2 / 0.6 / 0.087 / 0.024
	RTP 004 S T0050104199 RTP 004 S MS T0050102399		0.4 / 0.2 / 0.016 / 0.008	RTM 006 S MS T0050100499		0.6 / 0.4 / 0.024 / 0.016	RTU 032 S MS T0050106099		3.2 / 0.8 / 0.126 / 0.031
	RTP 008 S T0050104299 RTP 008 S MS T0050102499		0.8 / 0.3 / 0.031 / 0.012	RTM 008 S T0054460999N RTM 008 S MS T0054462399N		0.8 / 0.4 / 0.031 / 0.016	RTU 032 S L MS T0050106199		3.2 / 0.8 / 0.126 / 0.031
	RTP 010 S T0050104399 RTP 010 S MS T0050102599		1.0 / 0.3 / 0.039 / 0.012	RTM 008 S X T0054460599N RTM 008 S X MS T0054461999N		0.8 / 0.4 / 0.031 / 0.016	RTU 050 S MS T0050106299		5.0 / 1.2 / 0.197 / 0.047
	RTP 013 S T0050104499 RTP 013 S MS T0050102699		1.3 / 0.3 / 0.051 / 0.012	RTM 010 S T0050100599 RTM 010 S MS T0050100699		1.0 / 0.3 / 0.039 / 0.012	RTU 076 S MS T0050106399		7.6 / 1.5 / 0.299 / 0.059
				RTM 013 S T0054460399N RTM 013 S MS T0054461699N		1.3 / 0.4 / 0.051 / 0.016	RTU 093 S MS T0050106499		9.3 / 2.0 / 0.366 / 0.079
				RTM 013 S X MS T0054460373N		1.3 / 0.5 / 0.051 / 0.019			
				RTM 015 S T0054460499N RTM 015 S MS T0054461899N		1.5 / 0.4 / 0.059 / 0.016			
				RTM 018 S T0050100799 RTM 018 S MS T0050100899		1.8 / 0.4 / 0.071 / 0.016			
			RTM 022 S T0054460899N RTM 022 S MS T0054462299N		2.2 / 0.4 / 0.087 / 0.016				
			RTM 032 S T0050100999 RTM 032 S MS T0050101099		3.2 / 0.9 / 0.126 / 0.035				
			RTM 036 S T0054461999N RTM 036 S MS T0054463199N		3.6 / 0.9 / 0.141 / 0.035				
Knife 	RTP 010 K T0050104599 RTP 010 K MS T0050102799		1.0 / 0.039	RTM 025 K T0050101199 RTM 025 K MS T0050101299		2.5 / 0.098			
	RTP 010 K NW T0050104699 RTP 010 K MS NW T0050102899		1.0 / 0.039	RTM 030 K T0054460799N RTM 030 K MS T0054462199N		3.0 / 0.118			
	RTP 025 K T0050104799 RTP 025 K MS T0050102999		2.5 / 0.098						
Gullwing 	RTP 020 G T0050104899 RTP 020 G MS T0050103099		2.0 / 0.079	RTM 020 G T0054461999N RTM 020 G MS T0054462499N		2.0 / 0.079	RTU 020 G MS T0050106599		2.0 / 0.079

NO COMPROMISE.
PRECISION. PERFORMANCE. POWER.
 EXPLORE THE NEW ACTIVE SOLDERING TIP RANGE

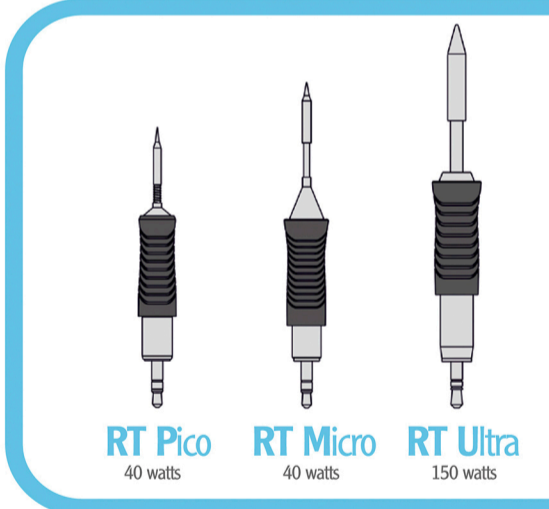

- Standard tip
- Mil-Spec soldering tip
- not wettable

Measuring tip



Blade

RTU 100 K MS T0050106699		10.0 / 0.393
RTU 160 K MS T0050106799		16.0 / 0.630
RTU 200 K MS T0050106899		20.0 / 0.078
RTU 330 K MS T0050106999		33.0 / 1.299

Weller®

www.weller-tools.com/nocompromise