

## Test Leads

Item no: 2181317 / 2181319 / 2305882 / 2305883 / 2305884

### Overview

Item no: 2181317 (black)


Item no: 2181319 (yellow)

Item no: 2305882 (red)

Item no: 2305883 (blue)

Item no: 2305884 (green)

∅ 4 mm

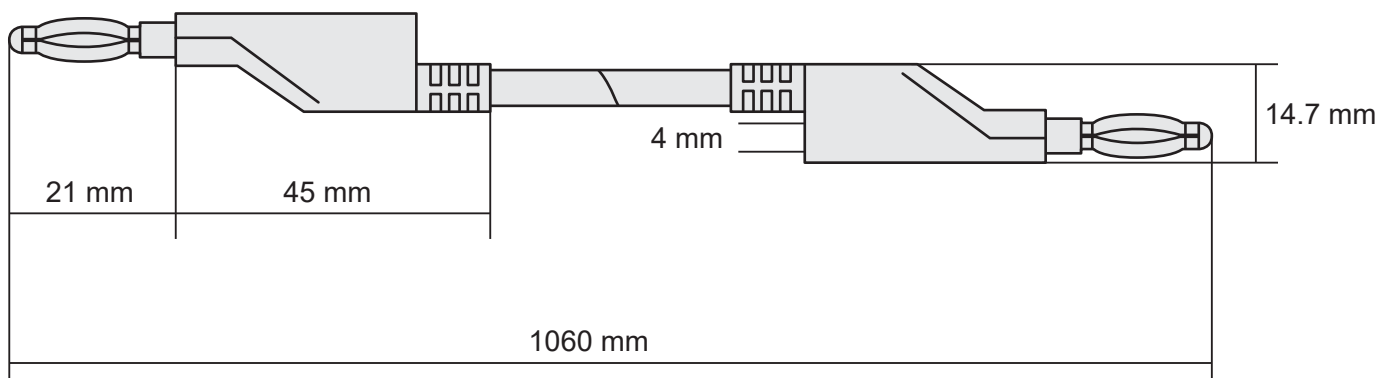

### Technical data

Type.....	FC-4
Line cross section.....	1 mm <sup>2</sup>
Connector diameter .....	∅ 4 mm plug
Connector type .....	stackable
Temperature range.....	0 to +80 °C
Rated current.....	10 A
Nominal current (rounded).....	10 A
Cable length .....	1 m
Connection A.....	Lamella plug, 4 mm
Port B.....	Lamella plug, 4 mm
Material.....	PVC
Measurement category.....	CAT I