

HWK-N4142TH-MH 2MP NETWORK CAMERA KIT



Features and Functions

Camera

- 1/2.8" progressive scan CMOS
- 1920 × 1080@30fps
- Up to 30 m IR range
- IP67

NVR


- H.265+/H.265 compression effectively reduces the storage space and costs
- Full channel recording at up to 4 MP resolution
- HDMI/VGA output at 1080p resolution
- 1-ch playback at 4 MP resolution or 2-ch at 1080p resolution
- 1 SATA hard disk can be connected with 6TB capacity
- 4 independent 100 Mbps built-in switch network interfaces



Specifications

Kit model		HWK-N4142TH-MH
NVR model		HWN-2104MH-4P
Camera model		4 * HWI-T220H
NVR		
Video input	IP Video input	4-ch
		Up to 4MP resolution
Network	Incoming bandwidth	40 Mbps
	Outgoing bandwidth	60 Mbps
Video output	Recording resolution	4 MP/3 MP/1080p/UXGA /720p/VGA/4CIF/DCIF/ 2CIF/CIF/QCIF
	HDMI/VGA output resolution	1920 × 1080p/60Hz, 1280 × 1024/60Hz, 1280 × 720/60Hz, 1024 × 768/60Hz
Decoding	Decoding format	H.265+/H.265/ H.264+/H.264
	Live view/Playback resolution	4 MP/3 MP/1080p/UXGA /720p/VGA/4CIF/DCIF/ 2CIF/CIF/QCIF
	Synchronous playback	4-ch
	Capability	1-ch @ 4 MP / 2-ch @ 1080p
Hard disk	SATA	1 SATA interface
	Capacity	Up to 6 TB capacity for each disk
External interface	Network interface	1, RJ45 10M/100M self-adaptive Ethernet interface
	USB interface	2 × USB 2.0
PoE Interface	Interface	4, RJ-45 10/100 Mbps self-adaptive Ethernet interface
	Power	≤36W
	Standard	IEEE 802.3 af/at
Camera		
Image sensor		1/2.8" progressive scan CMOS
Min. Illumination		Color: 0.01 Lux @(F1.2, AGC ON), 0.028Lux @ (F2.0, AGC ON)
Lens	2.8 mm	
	114.8°(H), 62°(V)	
Angle Adjustment		Pan: 0° to 360°, tilt: 0° to 75°, rotation: 0° to 360°
Video Compression		Main stream: H.265/H.264 Sub stream: H.265/H.264/MJPEG
Protection level		IP67
IR range		Up to 30 m
Power consumption and Current		12 VDC, 0.3 A, max: 3.5 W PoE: (802.3af, 36 V to 57 V), 0.2 A to 0.1 A, Max: 4.5 W
Materials		Camera body: metal, bottom base: plastic
Operating conditions		-30 °C to 60 °C (-22 °F to 140 °F), humidity: 95% or less (non-condensing)
Kit		
Accessories	Power	1pcs power cable, 1pcs power adaptor, 1pcs power transfer cable
	Cable	4 * 18.3 m (60 ft) video and power cable
Hard Drive		Pre-installed with Seagate ST1000VX001-520
Dimension (W × D × H)		415 x 210 x 310 mm (16.3 x 8.3 x 12.2 inch)

Physical Interfaces

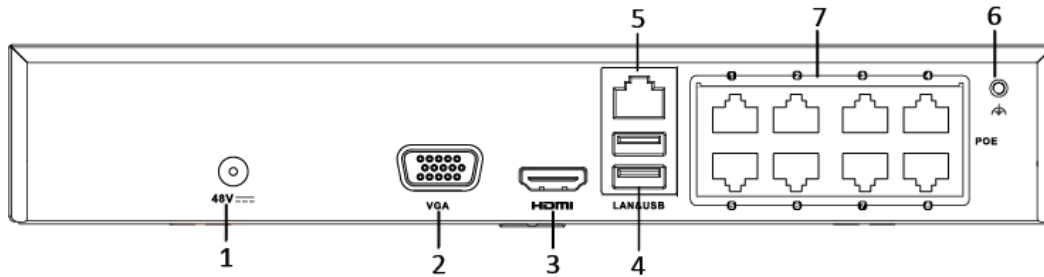

Index	Description	Index	Description
1	Power Supply	5	LAN Network Interface
2	VGA Interface	6	GND
3	HDMI Interface	7	Network Interfaces with PoE function (4 interfaces for HWN-2104MH-4P)
4	USB Interface	8	

Available Model

HWK-N4142TH-MH

Distributed by



Headquarters

No.555 Qianmo Road, Binjiang District,
Hangzhou 310051, China
T +86-571-8807-5998
overseasbusiness@hikvision.com

Hikvision USA
T +1-909-895-0400
sales.usa@hikvision.com

Hikvision Italy
T +39-0438-6902
info.it@hikvision.com

Hikvision Singapore
T +65-6684-4718
sg@hikvision.com

Hikvision Africa
T +27 (10) 0351172
sale.africa@hikvision.com

Hikvision Europe
T +31-23-55-42-770
info.eu@hikvision.com

Hikvision France
T +33(0)1-85-330-450
info.fr@hikvision.com

Hikvision Oceania
T +61-2-8599-4233
salesau@hikvision.com

Hikvision Hong Kong
T +852-2151-1761

Hikvision Middle East
T +971-4-8816086
salesme@hikvision.com

Hikvision Spain
T +34-91-737-16-55
info.es@hikvision.com

Hikvision Canada
T +1-909-895-0400
sales.usa@hikvision.com

Hikvision Russia
T +7-495-669-67-99
saleru@hikvision.com

Hikvision Poland
T +48-22-460-01-50
poland@hikvision.com

Hikvision Korea
T +82-31-731-8841
sales.korea@hikvision.com

Hikvision India
T +91-22-28469900
sales@pramahikvision.com

Hikvision UK
T +01628-902140
support.uk@hikvision.com

Hikvision Brazil
T +55 11 3318-0050
Latam.support@hikvision.com