
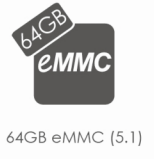
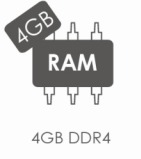
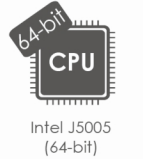


MINIX NEO J50C-4

Intel Pentium Silver Mini PC with Windows 10 Pro (64-bit)

Ideal Solution for Industrial and Commercial Applications

VESA Mount included for fast and easy installation

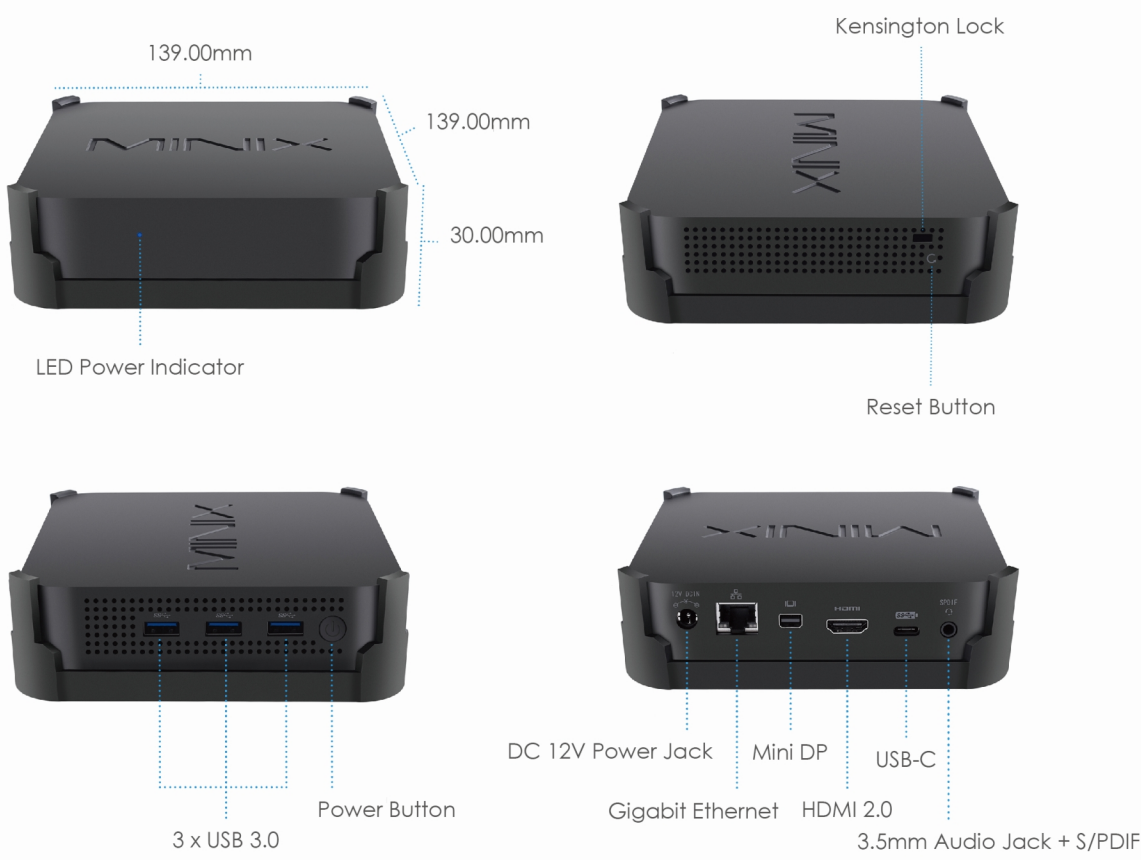

Processor	Intel Pentium Silver J5005 (64-bit)
GPU	Intel UHD Graphics 605
Memory	4GB DDR4 [upgradeable to 16GB]
Memory Slot	2 x SODIMM slot, dual channel support [each support up to 8GB]
Storage	64GB eMMC 5.1
Storage Expansion	1 x 2280 M.2 slot (SATA 6.0Gbps) [support up to 512GB]
Wireless Connectivity	802.11ac Dual-Band Wi-Fi, Bluetooth 4.1
Operating System	Windows 10 Pro (64-bit)
Video Output	HDMI™ 2.0 (4K @ 60Hz), Mini DisplayPort* (4K @ 60Hz), USB-C** (4K @ 60Hz)
Digital Audio Output	HDMI™ 2.0, Mini DisplayPort, Optical S/PDIF
Analog Audio Output	3.5mm Audio Jack
Audio Input	3.5mm Audio Jack
Peripheral Interface	RJ-45 Gigabit Ethernet, USB 3.0 port x 3, USB-C port x 1 Kensington Lock ready
Power	DC 12V, 3A (multihead adapter included) or via USB-C input (DC 12V)

*An active adapter is required to convert Mini DisplayPort output to HDMI/DVI output.

**The USB-C port only supports video output, not audio output.