

Smart Home Lights for Christmas and More

PLAYBULB string is a Bluetooth Smart APP controlled LED string lights for indoor and outdoor decoration. The lights are specially designed to make sure it works safely in wet environment or rainy day.

PLAYBULB string meets the needs of your color imagination with 16 million RGB colors and preset 4 light effects suiting with different occasions. The lights are dimmable, you can adjust the light brightness to fit environmental comfort. If you want to change the light colors, there are several ways to play! You can shake your smart phone or tap the color palette or capture any color in picture via PALYBULB X App. Besides, the timer function can schedule the light color and on / off. It supports group mode and cross-control function as well.

Every little creative point will make your life enjoyable and joyful! Comparing with other string lights, it is flexible that you are able to extend it from 10 meters to 20 meters by connecting extension string.

A portable power bank is enough to supply power for the string lights, which is convenient for outdoor use, such as camping.

Smart App Control

Download the PLAYBULB X App in App Store or Google Play Store. Color changing is at your finger tip. Choose your favourite effect. Choose your mood.



Special Effects

The PLAYBULB X App supports several special lighting and timer effects. Candleflickering, Pulsing, Dimming, Flashing, Rainbow, Rainbow Fading in different colors with a free adjustable speed.

Timer

You can easily trigger the on- and off-times with the App.


Safe and Energy Efficient

The modern LED technology makes the Playbulb String safe and also energy efficient in comparison with regular string bulbs.

Water Resistant

Integrity Protection Rating: IP65

You don't need to worry about spilling water or worst weather conditions. Hence it can be placed both indoors and outdoors. (excl. power adapter)

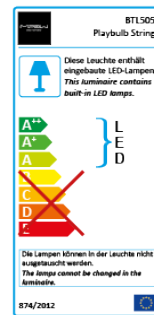

Group them to maximise Fun

PLAYBULB X App allows you to group multiple PLAYBULB devices and use one color panel.

Extendable

You can connect up to 2 PLAYBULB string extension packs of 5m length. Maximum total length: 20m

Internal Memory


The PLAYBULB string saves its last setting inside the internal memory. When turned off and on again, the PLAYBULB will automatically restore the last set effect or color.



Tech Details

Material	PVC
LED-Power	Max. 4W
LED-Colors	RGB (16 Mio. colors)
Number of LEDs	40 Stück
LED distance	25cm
Cable length (mains adapter)	150cm
Length LED String	10m
Max. length with Extension Set	20m
Input	USB mains adapter Input (100-240V AC 50/60Hz 0.5A Max.) Output (5.0V DC 2.0A Max.)
LED lifetime	At least 20.000 Stunden
Dimmable	Yes, via App
Time control	Yes, via App
Energy efficiency class	A++ to A
Operating temperature	-20 to 60°C
Bluetooth® Version	4.0 Smart
Bluetooth® Range	ca. 10 Meter
Field of application	In- and outdoors
IP safety class	IP65 (excl. mains adapter)
Compatibility Apple	iPhone 4s, iPad Air, iPad Mini and newer
Compatibility Android	All Smartphones and Tablets with Android 4.3 and newer
Android-App Link	https://play.google.com/store/apps/details?id=com.mipow.androidplaybulbcolor
iOS-App Link	https://itunes.apple.com/de/app/playbulb-x/id911359856
Youtube	https://www.youtube.com/watch?v=0s8GCtSmu80
Packaging contains	MiPow Playbulb String, USB mains adapter, Quick-Start-Guide (German/English)



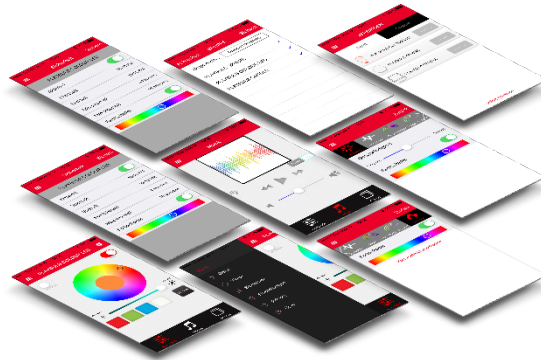

Additional Information

Art No.	Art. description	EAN	HS-Code
BTL505-GN	Playbulb String Basis 10 Meter, Green Edition	6945764511284	940530
BTL506-GN	Playbulb String Extension 5 Meter, Green Edition	6945764511499	940530
BTL505-WT	Playbulb String Basis 10 Meter, white, White Edition (Q1 / 2017)	6945764511529	940530
BTL506-WT	Playbulb String Extension 5 Meter, White Edition (Q1 / 2017)	6945764511512	940530



Measurements

Art No.	Product	Gift box	Master carton net	Master carton gross
BTL505	1 Stk. 5x2x1000mm 328g	1 Stk. 168x71x174mm 574g	20 Stk. 385x360x418mm 11.44kg	20 Stk. 385x360x418mm 13.13kg
BTL506	1 Stk. 5x2x500mm 167g	1 Stk. 123x57x144mm 229g	20 Stk. 310x270x350mm 4.44kg	20 Stk. 310x270x350mm 5.53kg



POS-Demo Unit

