
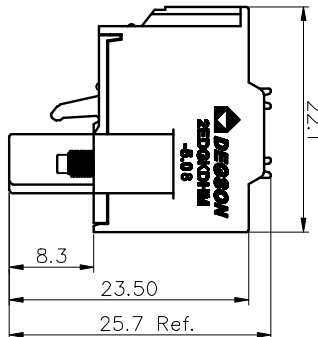
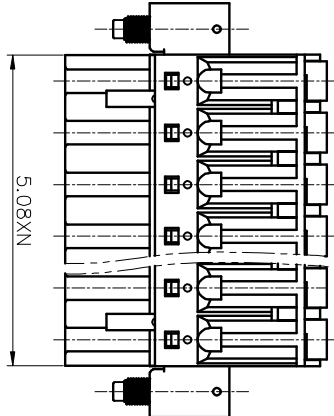
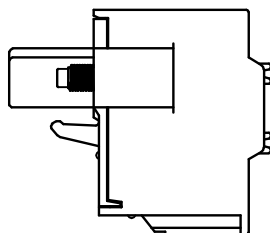


REVISION RECORD			
REV	ECN	DESCRIPTION	DRFT DATE

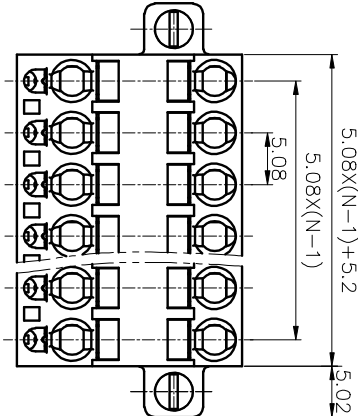

1. Pollution Degree	2
2. Overvoltage Category	III
3. Rate Impulse Voltage(kV)	4.0kV
4. Rate Voltage(V)	320V
5. Rate Current(A)	20A

- NOTES1:
- UL Standard
 - 1.Rated Voltage/Current : 300V / 12A
 - 2.Withstanding Voltage : AC1600V/1min.
 - 3. Wire Range : 26~12AWG
- IEC Standard
-

2. Wire Range : 0.2~2.5mm²


NOTES2:

- 1.Dimension shall be interpreted per ASME Y14.5-2009
- 2.Pitch : 5.08mm, Poles : N=02~24P
- 3.Stripping length : 9~10mm
- 4.Operating temperature: -40°C~+105°C
- 5.Undimensioned Tolerances:


Pitch	range	in mm	Nominal dimension	range	mm	in	mm
Over	6	10	Over	30	60	100	Over
10	TO	10	TO	TO	TO	TO	150
6	10	24	30	60	100	150	±2°
±0.15±0.20±0.30±0.30±0.50±0.70±1.00±1.30							

6. RoHS Compliance

ZEDGKDHM - 5.08 - XXP - 1Y - 00A (H)
(Series No.) (Pitch) (Poles) (Single Pitch) (Color): 1.(Grey)
2.(Blue)
3.(Black)
4.(Green)
5.(Orange)
6.(Red)
7.(Transparent)
8.(Yellow)
9.(White)

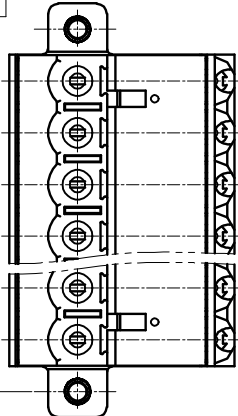

02/03P线结构图

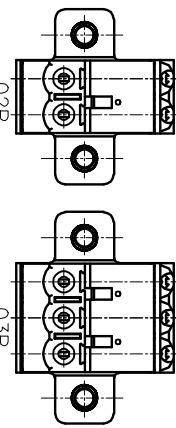

PART NO.:		NAME:	
/		NINGBO DESSON ELECTRICAL CO., LTD	
APPD:		TITLE:	
/		CUSTOMER DRAWING	
CHKD:		DRAWING NO.:	
/		DO NOT SCALE DRAWING	
DRFT:		SCALE	
/		1:1	

8 7 6 5 4 3 2 1