


Standard PVC Cable Set, 1.0mm²/2.5mm, 7 colors - assortment Item No. 19011CA089

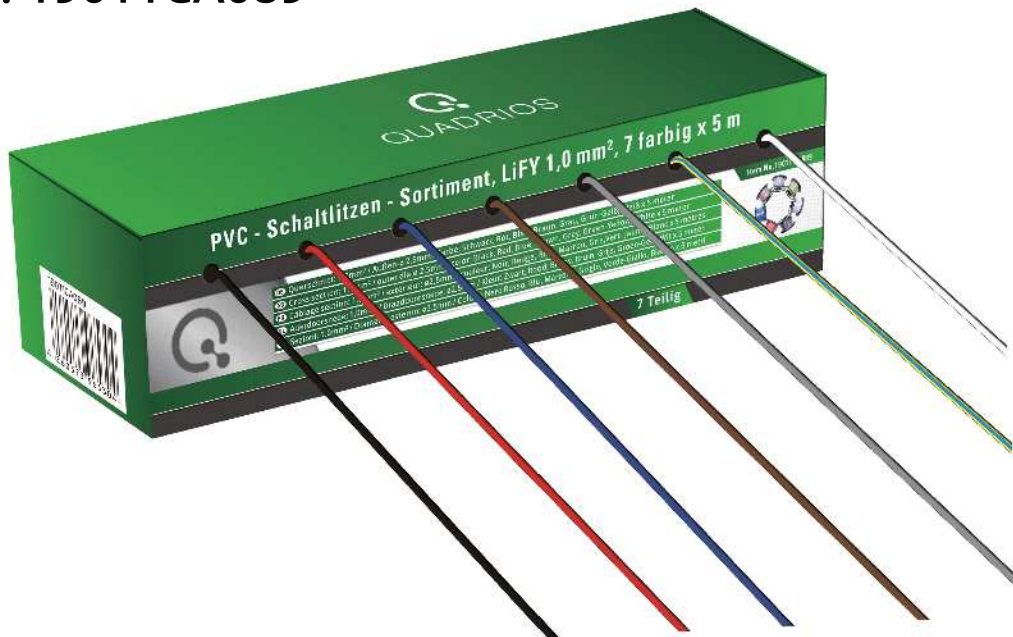

Core section: 1.0mm²
 External diameter: ø2.5mm
 No. of conductor: 32
 Conductor Diameter: 0.2mm
 Color: Black, White, Red, Blue, Brown, Grey, Yellow-Green
 Cable Length: 5 meter
 Insulation material: PVC
 Conductor material: Bare copper
 Insulation resistance: 200Mohm/km min.
 Dielectric strength: 2.5kv
 Rated temperature: 0°C - 80°C
 Rated voltage: 300V max.