


Standard PVC Cable Set, 0.75mm²/2.2mm, 7 colors - assortment Item No. 19011CA088

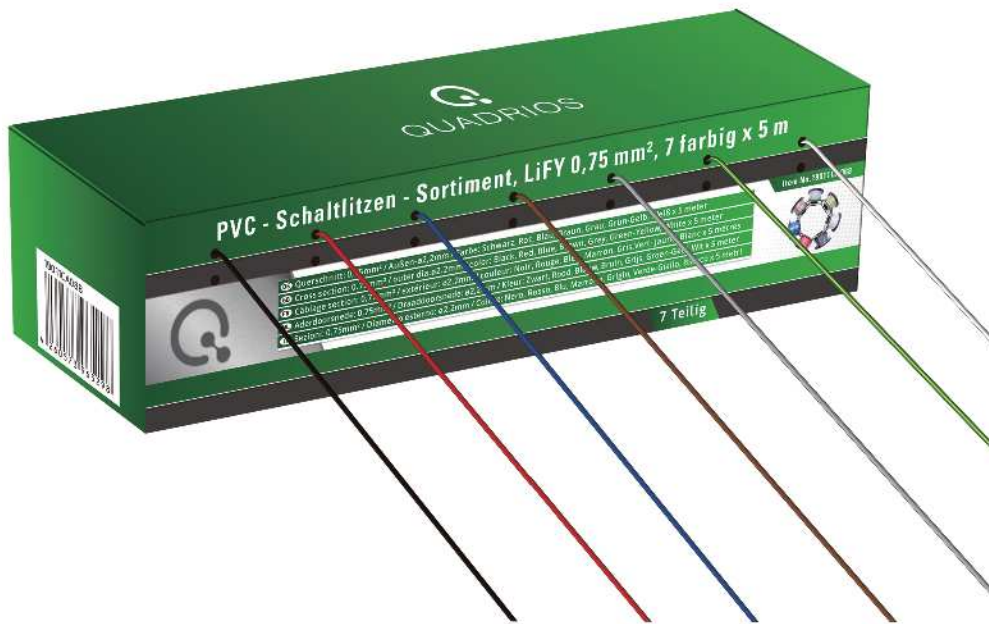

Core section: 0.75mm²

External diameter: ø2.2mm

No. of conductor: 96

Conductor Diameter: 0.1mm

Color: Black, White, Red, Blue, Brown, Grey, Yellow-Green

Cable Length: 5 meter

Insulation material: PVC

Conductor material: Bare copper

Insulation resistance: 200Mohm/km min.

Dielectric strength: 2.5kv

Rated temperature: 0°C - 80°C

Rated voltage: 300V max.