


Data Sheet

Low power connector socket

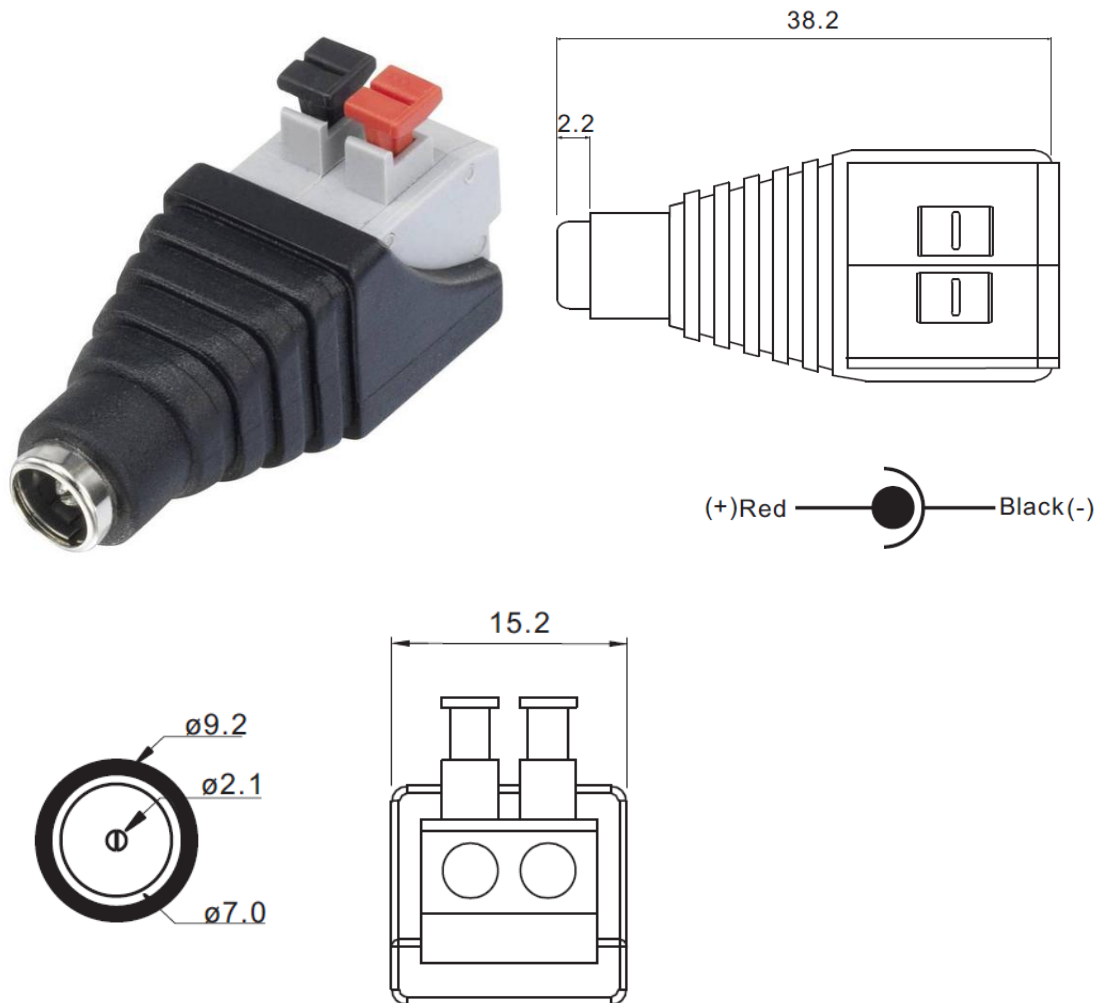

Technical data

Voltage rating: 12VDC

Current rating: 5A

Contact resistance: 20mΩ

Insulation resistance: 5000MΩ / 1000V

Wire range: 22-16AWG

Torque: 0.5Nm (4.4lb/in)

Operating temperature: -40°C to 105°C

Strip length: 8-9mm