


Data Sheet

Push button switch

Version 01/25

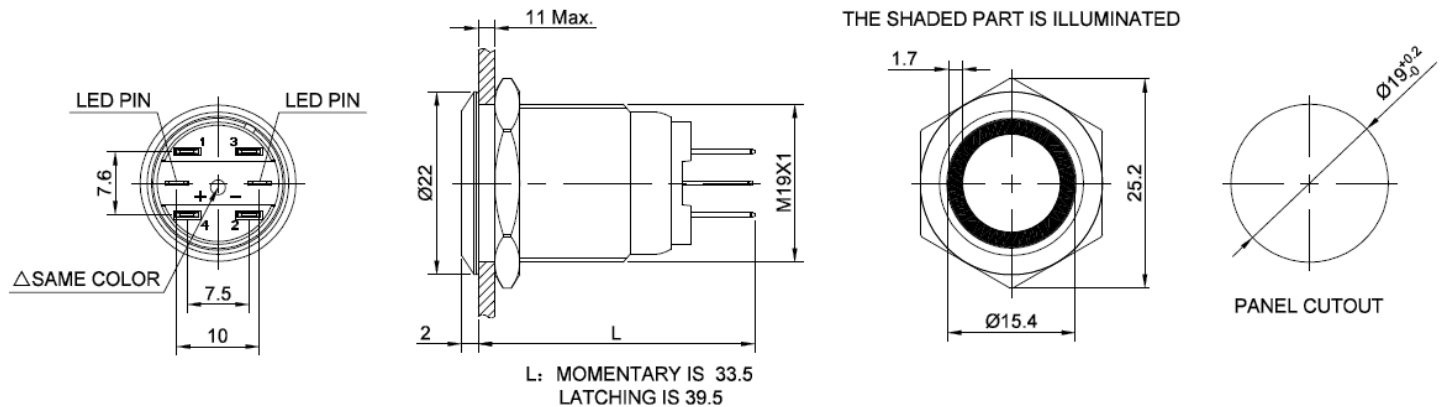

11 MAX: means the panel thickness, the max thickness for the panel no more than 11mm.

Specification

Mounting diameter	19 mm
Head shape	Flat round head
Operation type	Momentary
Contact structure	1NO1NC
Switch rating	250VAC / 5 A
Illumination type	Ring
Body material	Stainless steel
Operating and storage temperature	-20 to +55 °C
Operating and storage humidity	45 to 85 % RH
Base material	PC
IP rating	IP65

Item no.	LED color	LED voltage
2207814	Red	12 V
2226166	Green	12 V
2226167	Blue	12 V