


## Data Sheet

### Push button switch

Version 01/25

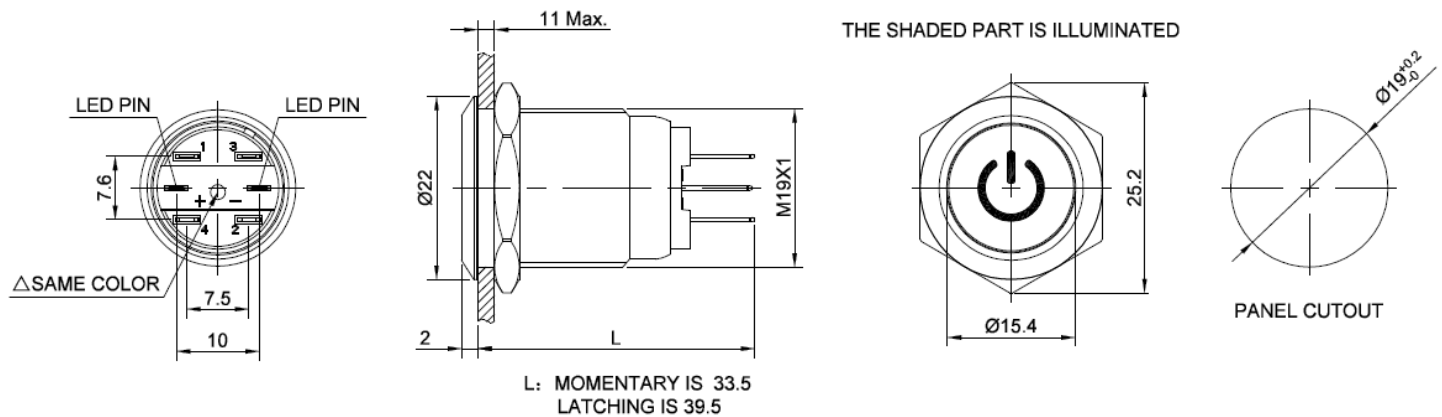

11 MAX: means the panel thickness, the max thickness for the panel no more than 11mm.

### Specification

|                                         |                 |
|-----------------------------------------|-----------------|
| Mounting diameter .....                 | 19 mm           |
| Head shape .....                        | Flat round head |
| Operation type .....                    | Momentary       |
| Contact structure .....                 | 1NO1NC          |
| Switch rating .....                     | 250VAC / 3 A    |
| Illumination type .....                 | Power Symbol    |
| Body material .....                     | Stainless steel |
| Operating and storage temperature ..... | -20 to +55 °C   |
| Operating and storage humidity .....    | 45 to 85 % RH   |
| Base material .....                     | PC              |
| IP rating .....                         | IP65            |

| Item no. | LED color | LED voltage |
|----------|-----------|-------------|
| 2226170  | Green     | 12 V        |
| 2226171  | Blue      | 12 V        |