
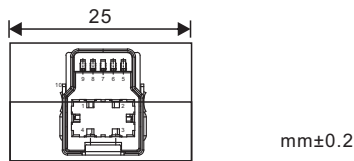
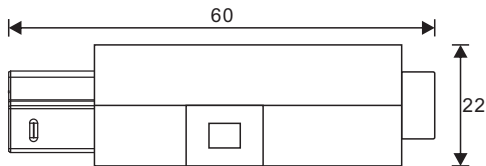
 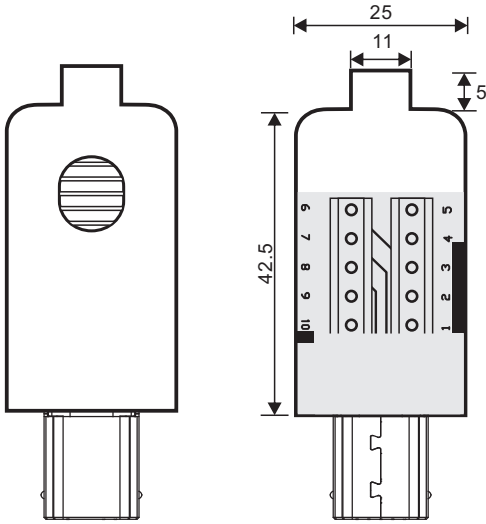


USB B type, 3.0 Male Connector modular

Item No. 2001C204



	1	2	3	4	5	6	7	8	9	10
	VBUS	D-	D+	GND	StdB_SSTX-	StdB_SSTX+	GND_DRAIN	StdB_SSRX-	StdB_SSRX+	Shield

Note: Tx and Rx are defined from the device perspective



Material:
 Housing: PP
 Insulator: PBT
 Connector shell: SPCC with Ni plated
 Contact: Brass with plated Au1μ/Sn100-120μ
 Technical:
 Voltage rating: 30V max.
 Current rating: 1.0A max.
 Contact resistance: 30mΩ max.
 Insulation resistance: 100MΩ min.
 Dielectric withstanding voltage: 300V/AC
 Operation temperature: -20 ~85°C