
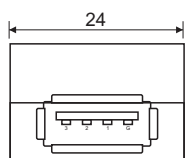
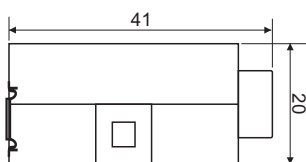


USB A type, 2.0 Female Connector modular

Item No. 2001C199

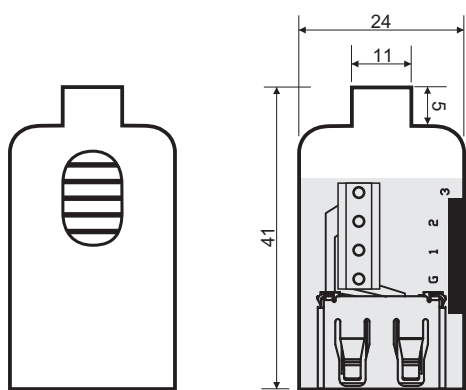

mm±0.2

	3	2	1	G
	VBUS	D -	D +	GND



Screwdriver Included



Material:

Housing: PP

Insulator: PBT/LCP

Connector shell: SPCC with plated Ni 40μ min.

Contact: Brass with plated Au1μ

Technical:

Voltage rating: 5V max.

Current rating: 2A max.

Contact resistance: 30mΩ max.

Insulation resistance: 1000MΩ min.

Dielectric withstanding voltage: 500V/AC(R.M.S)

Operation temperature: -20 ~85°C