



i3UV EOS

Mono-output Keychain Ultraviolet Light



i3UV EOS

Mono-output Keychain Ultraviolet Light



MARKET APPLICATIONS

Outdoors
Household

UPC: 697237812053 3

MSRP: \$14.95

DESCRIPTION

The i3UV is an extremely compact ultraviolet flashlight. Powered by a single AAA battery, this ultra-compact designed UV light emits an average wavelength of 395 nanometer. Made of durable aircraft-grade aluminium, this little light is strong and durable. The versatile i3UV can be carried along to detect invisible stains, find scorpions and minerals, etc. Get one in your hands to explore more!

A6061-T6 Aluminum Alloy Body



High Efficiency UV Led



Positive Polarity Mark

FEATURES

- **Versatile Use:** High efficiency 395nm ultraviolet LED. Perfect for revealing invisible stains, finding scorpions and minerals, etc.
- **Practical Design:** Made of durable aircraft-grade aluminium, and IPX8 waterproof, making it strong and long-lasting.
- **Light and Tiny:** Ultra-compact design provides easy connection to a keychain for every day carry.
- **Easy-to-reach Power:** Fully tighten the head to turn flashlight on. Slightly loosen the head to turn flashlight off.

LIGHT SOURCE

High efficiency 395nm UV LED

BODY MATERIAL

Aluminum Alloy

DIMENSION

Length: 2.38in/60.5mm
Head Diameter: 0.55in/14mm
Body Diameter: 0.49in/12.5mm

POWERED BY

AAA Alkaline Battery (included)

WEIGHT

0.68 oz/19.4g(including battery)


WARRANTY

Olight's 5 Years Warranty
Visit: <https://olightworld.com/olight-warranty>

IN THE BOX

Flashlight i3UV EOS(with battery) x 1
User Manual x 1

WATERPROOF IPX8

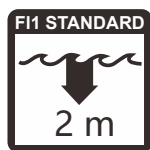

DROP TEST



COMPLIANCE



The above data are test results retrieved according to ANSI NEMA FL 1-2009 standards.