




Designation:..... **18761 101 001 (hang tag)**

Battery requirement: 6xAA / 3xAA Alkaline battery

Bulb required: 1 pcs 6W Mid-power COB 6500K cool white LED

Mode 6AA	High	Med	Low	Night
Luminous intensity (lm) (with lens off)	450	240	45	15
Beam range (m)	20	15	6.5	4
Range: (calculated distance at maximum luminous intensity with an illuminance of 0.25 lux)				
Mode 3AA	High	Med	Low	Night
Luminous intensity (lm) (with lens off)	350	180	35	12
Beam range (m)	17	13	6	3.5

For use with only 3AAs:
Place batteries in positive position & 2 near negative positions of the battery cartridge

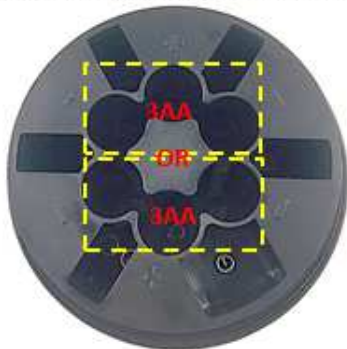

Weight: 623 g (without batteries)

Material:..... ABS (Acrylnitril-Butadien-Styrol)
PP + TPE
PC (Polycarbonate)

Dimensions:..... **A: 98.3 mm**
B: 107.2 mm
C: 215 mm

Run Time:..... **6AA (with Varta LLP)**

High: 18 h
Med: 40 h
Low: 190 h
Night: 360 h

3AA (with Varta LLP)

High: 12 h
Med: 16 h
Low: 100 h
Night: 220 h

Features:

1pcs Mid-power COB cool white LED / Eye risk group 0 exempt group)

MCU control Push switch (High/Medium/Low/Off, Night mode/Off)

Double click go into night model directly

Ambidextrous handle can be flipped up from either side

Integrated hook in lantern base

Extra thick housing & over mould rubber for maximum durability

4 meters (13.2 feet) impact resistant / IP67 dust proof & water proof

Pass IK08 impact / Passed extreme temperature shock test

10,000 switch cycle test

No publication or circulation of data to third parties without consent of VARTA Consumer Batteries