


## ESD Grounding Cord

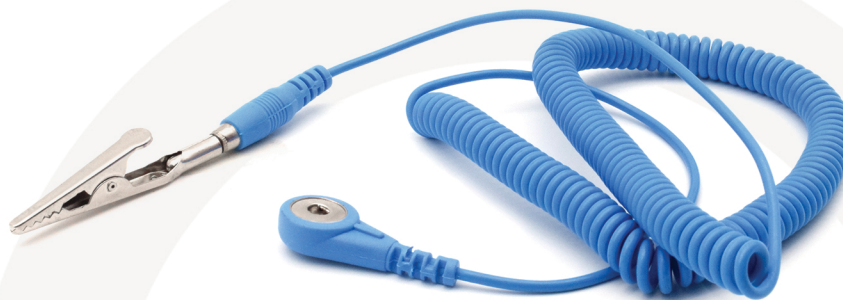

Item No	Cable Length(mm)	Termination Type	Stud Size
1903EC011	1800	Banana Plug with Alligator Clip	4mm
1903EC012	3600		4mm
1903EC013	1800		10mm
1903EC014	3600		10mm

### Specifications:

Cable Style: Spiral cable

Wire Type: Single Wire

Color: Light Blue

Insulation: Polyurethane (Non-Conductive)

Use Type: Reusable

All the cables can withstand 1250 volts DC for at least one minute

### Application:

ESD Grounding Cords shall be used to make electrical connections between groundable points and the ESD Grounding facility

*\*Unless otherwise noted, tolerance  $\pm 10\%$   
Specifications and procedures subject to change without notice*