




Hikvision Fast Fever Screening Solution for Factory

>>> Solution Introduction

The Solution uses thermal camera deployed in the factory entrance and the working place to detect person with abnormal body temperature and then to take further guidance for the suspected fever patients.

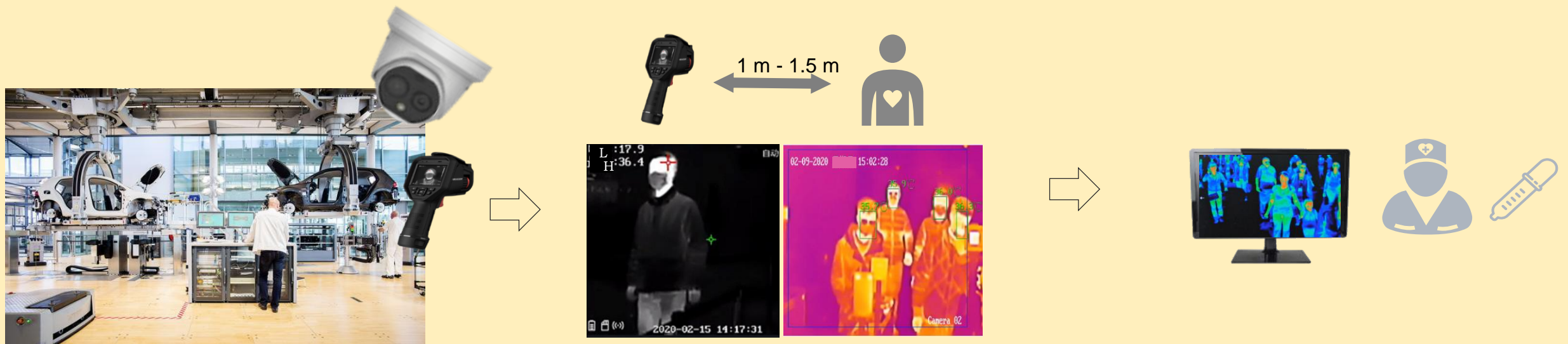



Handheld fever screening by patrolling inspectors or fixed checking spot in the factory's entrance & exit

Skin-temperature based detection in high accuracy ($\pm 0.5^{\circ}\text{C}$) without surrounding interference

Fast fever screening with elevated temperature alarm (pop-up image/audio warning)

>>> Solution Components


or


Thermographic Handheld Camera

- Distance : 1.5-2.5 m
- Efficiency: 60 persons/min
- Accuracy: $\pm 0.5^{\circ}\text{C}$
- Range: 30-45°C
- Supports audio alarms
- Wi-Fi supported

HD Turret Fever Screening Thermographic Camera

- Accuracy: $\pm 0.5^{\circ}\text{C}$
- Measurement range: 30-45°C
- Supports temperature-exception audio alarms
- AI human body detection, screening multiple targets at the same time






Network Video Recorder

- Supports temperature triggered alarm
- Pop-up Image and audio warning for temperature exceptions





LED Monitor

- 21.5" 1080P, HDMI/VGA input, BNC in, BNC out
- build-in speaker
- Multiply inputs: HDMI, VGA