


SAUTER CO 5-Y4

Miniature cylindrical load cell made from stainless steel

KERN

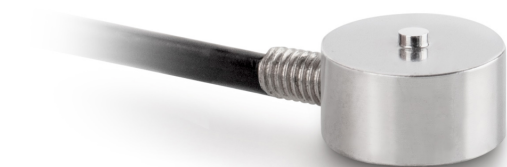

Construction

Material	steel, stainless
Design	Load cell
Cable length	2 m
Mounting - force application	Thrust piece (from customer side)
Mounting - force dissipation	Mold nest

Environmental conditions

Use temperature [Min]	0 °C
Use temperature [Max]	40 °C

Approval

CE mark	✓
---------	---

Services (optional)

Article number for DAkkS calibration (compressive force)	963-261V
--	----------

Product information

GTIN/EAN number	4045761232884
REACH classification	no prohibited substances

Packing & Shipping

Shipping method	Parcel service
Delivery time	1 d
Dimensions packaging (W×D×H)	150×100×38 mm
Net weight approx.	0,05 kg
Gross weight approx.	0,10 kg
Shipping weight	0,1 kg

Pictograms

STANDARD



OPTION



Category

Brand	Sauter
Product category	Measuring cell
Product group	Load/force measuring cell
Product family	CO Y4

Measuring System

Weighing capacity [Max]	5 kg
Measuring range force [Max] (N)	50 N
Load cell - characteristic value - nominal	1 mV/V
Load cell OIML class	G5
Load cell connection	4-wire
Measuring applications	force mass
Directions of force	compression
Load cell - Input resistance - nominal	350 Ω
Load cell - Input resistance - variance	20 Ω
Load cell - Output resistance - nominal	350 Ω
Load cell - Output resistance - variance	3 Ω
Load cell - Recommended excitation voltage [Min]	9 V
Load cell - Recommended excitation voltage [Max]	12 V
Load cell - Isolation resistance - [Min]	5000 MΩ
Load cell - Combined error	0,5%

Functions

IP protection - complete device	IP67
---------------------------------	------